


BJ746

SOCKET TOGGLE SCREWS

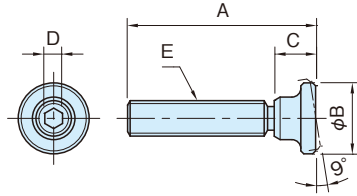

Type	Body	Foot
BJ746	Steel (SCM435) Quenched and tempered Black oxide finish	Steel (S45C) Quenched and tempered Black oxide finish
BJ746-SUS	Stainless Steel (SUS304)	

Steel	Stainless Steel	A	B	C	D	E	weight (g)
Part Number	Part Number						
BJ746-06001	BJ746-06001-SUS	27	12	7	3	M 6×1	9
BJ746-06002	BJ746-06002-SUS	42					13
BJ746-08001	BJ746-08001-SUS	43	16	9	4	M 8×1.25	28
BJ746-08002	BJ746-08002-SUS	63					37
BJ746-08003	BJ746-08003-SUS	83					46
BJ746-10001	BJ746-10001-SUS	64	20	11	5	M10×1.5	50
BJ746-10002	BJ746-10002-SUS	84					60
BJ746-10003	BJ746-10003-SUS	104					70
BJ746-12001	BJ746-12001-SUS	65	25	13	6	M12×1.75	75
BJ746-12002	BJ746-12002-SUS	85					95
BJ746-12003	BJ746-12003-SUS	105					110
BJ746-12004	-	130					130
BJ746-16001	-	85	32	15	8	M16×2	170
BJ746-16002	-	105					190
BJ746-16003	-	130					230
BJ746-16004	-	155					265
BJ746-20001	-	105	40	16	10	M20×2.5	310
BJ746-20002	-	130					360
BJ746-20003	-	155					410

Application Example

