


**BJ764****KNURLED HEAD SCREWS**

(Steel)



(Stainless Steel)

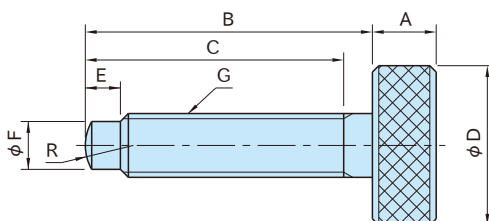

Type	Body
<b>BJ764</b>	Steel (S45C) Quenched and tempered Black oxide finish
<b>BJ764-SUS</b>	stainless steel (SUS440C) Induction hardened (on edge)

Steel	Stainless Steel	A	B	C	D	E	F	G	R	Weight (g)
Part Number	Part Number									
<b>BJ764-05001</b>	<b>BJ764-05001-SUS</b>	6	25	23	16	3	4	M 5×0.8	R 4	12
<b>BJ764-05002</b>	<b>BJ764-05002-SUS</b>		40	38						14
<b>BJ764-06001</b>	<b>BJ764-06001-SUS</b>	7	35	33	18	3.5	4.5	M 6×1	R 5	19
<b>BJ764-06002</b>	<b>BJ764-06002-SUS</b>		50	48						21
<b>BJ764-08001</b>	<b>BJ764-08001-SUS</b>	8	45	42	20	5	6	M 8×1.25	R 6	31
<b>BJ764-08002</b>	<b>BJ764-08002-SUS</b>		60	57						35
<b>BJ764-10001</b>	<b>BJ764-10001-SUS</b>	10	45	42	25	5.5	7.5	M10×1.5	R 8	57
<b>BJ764-10002</b>	<b>BJ764-10002-SUS</b>		60	57						64
<b>BJ764-12001</b>	<b>BJ764-12001-SUS</b>	12	60	56.5	32	6.5	9	M12×1.75	R10	125
<b>BJ764-12002</b>	<b>BJ764-12002-SUS</b>		80	76.5						140
<b>BJ764-16001</b>	-	16	80	76	40	8.5	12	M16×2	R12	275
<b>BJ764-16002</b>	-		100	96						305