
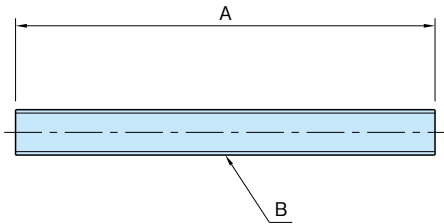


BJ830

FULLY-THREADED BARS

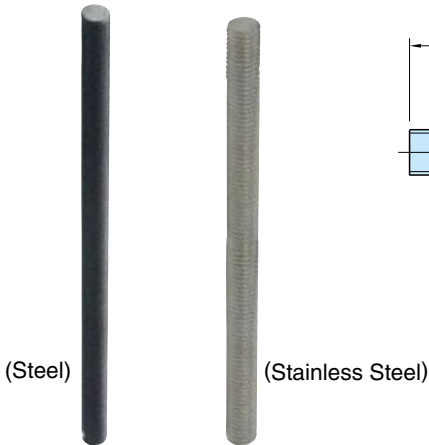

Type	Body
BJ830	Steel (SNB7) Quenched and tempered Black oxide finish
BJ830-SUS	Stainless steel (SUS304)

Steel	Stainless Steel	A	B	Weight (g)
Part Number	Part Number			
	BJ830-08230-SUS	230	M 8×1.25	90
	BJ830-08320-SUS	320		125
	BJ830-08490-SUS	490		190
BJ830-10320	BJ830-10320-SUS	320	M10×1.5	145
BJ830-10490	BJ830-10490-SUS	490		225
BJ830-10010	BJ830-10010-SUS	1,000		450
BJ830-12320	BJ830-12320-SUS	320	M12×1.75	210
BJ830-12490	BJ830-12490-SUS	490		320
BJ830-12010	BJ830-12010-SUS	1,000		660
BJ830-16320		320	M16×2	390
BJ830-16490		490		600
BJ830-16010		1,000		1,220
BJ830-20320		320	M20×2.5	620
BJ830-20490		490		940
BJ830-20010		1,000		1,900
BJ830-24320		320	M24×3	1,110
BJ830-24490		490		1,700
BJ830-24010		1,000		3,450

Note:
Both ends of steel studs are not surface finished.

Technical Information

Tensile Strength
BJ830 : 860N/mm²
BJ830-SUS: 480N/mm² or more