


BSRJ-SUS

BALL SCREWS, Plastic Ball

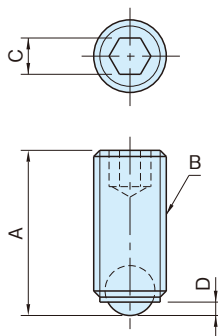

Body	Ball
Stainless steel(SUS303)	Polyacetal plastic

Part Number	Ball Dia.	A	B	C	D	Weight (g)
BSRJ4× 6-SUS	Sφ2.5	6	M4×0.7	2	0.4	0.4
BSRJ4×10-SUS		10				0.7
BSRJ4×16-SUS		16				1.1
BSRJ5× 8-SUS	Sφ3	8	M5×0.8	2.5	0.7	0.8
BSRJ5×12-SUS		12				1.3
BSRJ5×20-SUS		20				2.3
BSRJ6×10-SUS	Sφ4	10.8	M6×1	3	0.9	1.5
BSRJ6×16-SUS		16.8				2.4
BSRJ6×20-SUS		20.8				3
BSRJ6×25-SUS		25.8				3.9
BSRJ8×10-SUS	Sφ5.5	11.2	M8×1.25	4	1.4	2.6
BSRJ8×12-SUS		13.2				3.2
BSRJ8×20-SUS		21.2				5.7
BSRJ8×25-SUS		26.2				7.3
BSRJ8×30-SUS		31.2				8.9

• Heat resistance : 95°C