




EFHC PLASTIC HINGES




ELESA Original Design CFP. & CFQ.




Body & Pivot Pin	Cover
Polyacetal plastic Black Matte	Polybutylene terephthalate plastic (PBT)

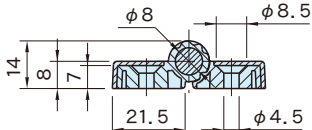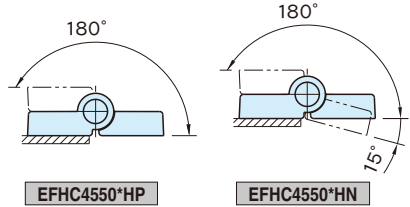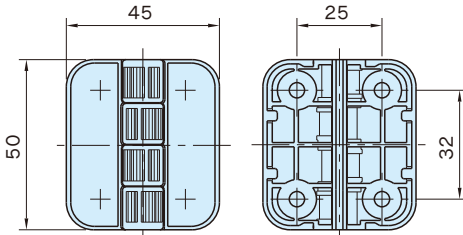


EFHC4550SHP

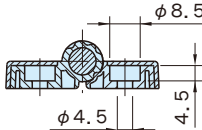

EFHC4550CHP

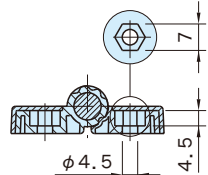

EFHC4550EHP

 


EFHC4550SHN

(Countersunk-Head-Screw Holes)



EFHC4550CHN

 (Hex.-Socket-Head-Cap-Screw Holes)




EFHC4550EHN

(Hex.-Head-Screw Holes)

Part Number	Choices of Detent Position	Weight (g)
EFHC4550SHP	4	17
EFHC4550CHP		
EFHC4550EHP		
EFHC4550SHN	0	17
EFHC4550CHN		
EFHC4550EHN		

 • **EFHC4550*HP** types have 4 choices of detent position : 0°, 80°, 120° and 170°. All detent positions accept a positioning torque of 1.1Nm.



- Pivot angle : Max. 180° for **EFHC4550*HP** types
Max. 195° for **EFHC4550*HN** types
- Working temperature : Between -20°C and 60°C

