

EW / EW-SUS


END-FIXING PLATES



EW
(Steel)



EW-SUS
(Stainless Steel)

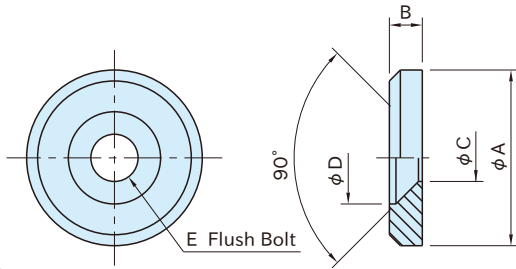

| Type | Body |
|---------------|------------------------------------|
| EW | SUM22L steel Black oxide finish |
| EW-SUS | SUS303 stainless steel |

| Steel | Stainless Steel | A | B | C | D | E | Weight (g) |
|----------------|--------------------|----|-----|-----|-----|----|------------|
| Part Number | Part Number | | | | | | |
| EW04×16 | EW04×16-SUS | 16 | 3 | 4.3 | 8.4 | M4 | 3.5 |
| EW04×20 | EW04×20-SUS | 20 | | | | | 6 |
| EW05×22 | EW05×22-SUS | 22 | 3.5 | 5.3 | 10 | M5 | 8.5 |
| EW05×25 | EW05×25-SUS | 25 | | | | | 12 |
| EW05×28 | EW05×28-SUS | 28 | | | | | 15 |
| EW06×32 | EW06×32-SUS | 32 | 4 | 6.4 | 12 | M6 | 22 |
| EW06×36 | EW06×36-SUS | 36 | | | | | 29 |
| EW06×40 | EW06×40-SUS | 40 | 5 | 6.4 | 12 | M6 | 46 |
| EW06×45 | EW06×45-SUS | 45 | | | | | 71 |
| EW06×52 | EW06×52-SUS | 52 | 6 | | | | 94 |

How To Use:

