


GRL-S2-D

TAPERED GUIDE ROLLERS (DOUBLE BEARINGS)

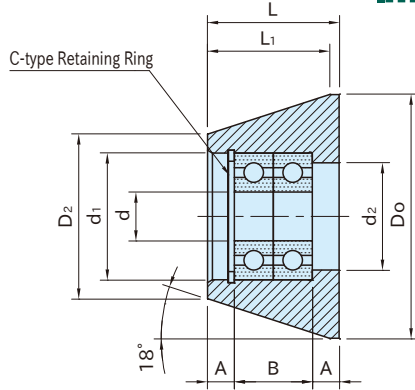

Body	Bearing/Retaining Ring
S45C steel Electroless nickel plated	Steel

Part Number	d	Do	D2	d1	d2	L	L1	A	B	Bearing Type	Weight (g)	Applicable Roller Screws
GRL50S2-D	10	50	33.8	26	22	27	25	5.5	16	6000ZZ×2	235	RLB1016
GRL60S2-D	12	60	39.9	32	26	33	31	6.5	20	6201ZZ×2	405	RLB1220
GRL70S2-D	15	70	46	35	29	39	37	8.5	22	6202ZZ×2	650	RLB1522

Features:

- Use as rollers for carriers.
- Heavy-duty

Technical Information:

Load Rating of Bearings

Bearing Type	Basic Load Rating Cr (N)	Basic Static Load Rating Cor (N)
6000ZZ×2	7370	3190
6201ZZ×2	11010	4940
6202ZZ×2	12390	5990

Related Product Page

Applicable Roller Screws

RLB ROLLER SCREWS

Application Example

