

MHS / MCT / MFSC ANGLE GRIPPERS



MHS -127-4



MHS -127-12



MHS -130-4



MCT -127-4



MCT -127-12



MCT -130-4



MFSC -127-4




MFSC -127-10




MFSC -130-4


Type	Body	Insert Tip
MHS	Steel (SKH51) Quenched and tempered Black oxide finish Heat treated to Rc62	
MCT	Steel (SKH51) Quenched and tempered Black oxide finish Heat treated to Rc62	Carbide Heat treated to Rc72
MFSC	Carbide Heat treated to Rc72	

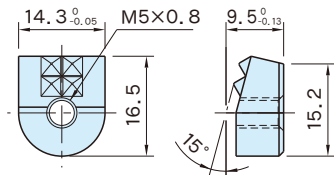


MHS -127-4

 


MHS -127-12

 


MHS -130-4

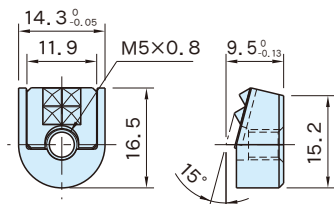


MCT -127-4

 


MCT -127-12

 


MCT -130-4

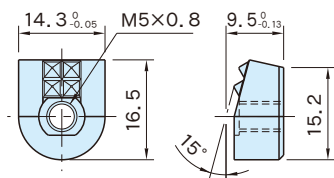

MFSC -127-4

 

MFSC -127-10

 

MFSC -130-4

MHS	
Part Number	Weight (g)
MHS-127- 4	11
MHS-127-12	12
MHS-130- 4	

MCT	
Part Number	Weight (g)
MCT-127- 4	12
MCT-127-12	13
MCT-130- 4	

MFSC	
Part Number	Weight (g)
MFSC-127- 4	20
MFSC-127-10	
MFSC-130- 4	