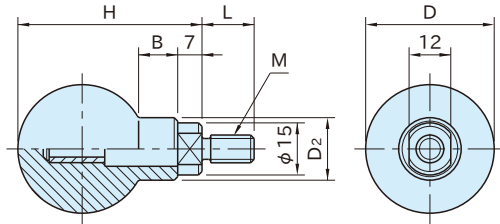


RBG**REVOLVING BALL KNOBS**Original ELESA Model P.111+x 

Body	Shank
Phenolic plastic Glossy Finish Black	Steel(SUM22L) Zinc plated

Part Number	D	M	D ₂	H	B	L	Weight (g)
RBG37	37	M 8×1.25	18	54	13	15	55
RBG47	47	M10×1.5	23	69	17	17	130

Technical Information

Working temperature : -20°C to 110°C