

# RG,RGS


# REVOLVING HANDLES




Original ELESA Model I.281+x, I.301+x, I.601+x




**RG**  
(Phenolic)

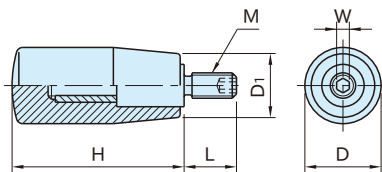

**RG**  
(Phenolic)

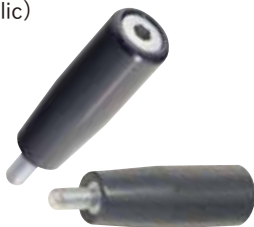


**RGS**  
(Phenolic)

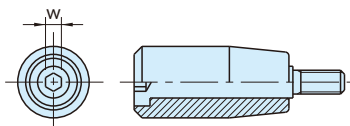

**RGS**  
(Phenolic)



 **RG-N**  
(Polypropylene)



**RG-N** **RG-N-SUS**  
(Polypropylene)

Type	Handle	Shank
<b>RG</b>	Phenolic plastic Glossy Finish	Steel(SUM22L)
<b>RGS</b>	Black	Zinc plated
<b>RG-N</b>	Polypropylene plastic	Stainless steel(SUS303)
<b>RG-N-SUS</b>	Black matte	

**RG** (Phenolic)

Part Number	D	M	D <sub>1</sub>	H	L	W	Weight (g)
<b>RG 28</b>	14	M 6×1	11	28	10	3	13
<b>RG 40</b>	18		15	40	13		27
<b>RG 50</b>	21		17	50			37
<b>RG 65</b>	23	M 8×1.25	19	65	15	4	75
<b>RG 80</b>	26	M10×1.5	21	80	17	5	98
<b>RG 90</b>	28		22	90			118
<b>RG115</b>	29		23	116			143