


# TBD1

# TURN BUCKLES, DOUBLE-END

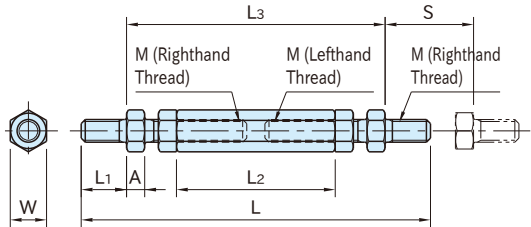

Bolt	Long Hex Nut	Hex Nut
Steel(S45C) Black oxide finish Heat treated to Rc33 - 39	Steel(S45C) Black oxide finish Heat treated to Rc33 - 39	Steel

Part Number	M	S	L <sub>3</sub>	L	L <sub>1</sub>	L <sub>2</sub>	W	A	Weight (g)
<b>TBD1-M 5</b>	M 5×0.8	21	62	82	10	40	8	4	25
<b>TBD1-M 6</b>	M 6×1	23	74	98	12	45	10	5	45
<b>TBD1-M 8</b>	M 8×1.25	32	97	129	16	60	13	6.5	105
<b>TBD1-M10</b>	M10×1.5	41	120	160	20	75	17	8	225
<b>TBD1-M12</b>	M12×1.75	51	143	191	24	90	19	10	350
<b>TBD1-M16</b>	M16×2	68	190	254	32	120	24	13	760
<b>TBD1-M20</b>	M20×2.5	86	236	316	40	150	30	16	1,430

## How To Use

Use to adjust the position of slides or rod ends.