


TC-SB

ANGLE BRACKE

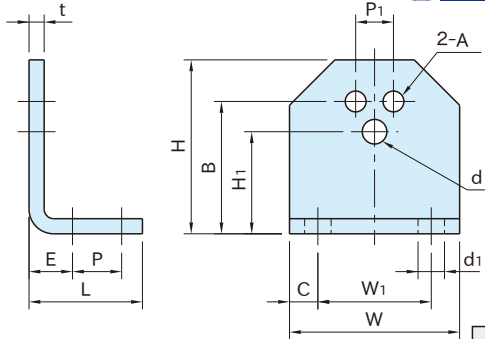

*Use the hole "d" to mount Fixed Tighteners.
(The holes "2-A" are not used.)

Body
Steel(SS400)
Hammerstone finish
Gray

Part Number	d	H ₁	H	W	L	t	d ₁	P	W ₁	C	E	P ₁	A	B	Weight (g)
TC-SB10	6.5	27	46	45	30	4	7	13	30	7.5	11.5	10	5.5	35	90
TC-SB20	8.5	34	58	55	32	5			40		13.5	12	6.5	44	170
TC-SB30	10.5	43	74	70	38	6	9.5	15.5	50	10	16.5	20	8.5	55	290
TC-SB40	12.5	57	98	90	52	8	11.5	21.5	65	12.5	21	25	10.5	75	720

Part Number	Proper Fixed Tighteners		
TC-SB10	TC-RE10	-	TC-PX10
TC-SB20	TC-RE20	TC-CEP20	TC-PX20
TC-SB30	TC-RE30	TC-CEP30	TC-PX30
TC-SB40	TC-RE40	TC-CEP40	-

How To Use

