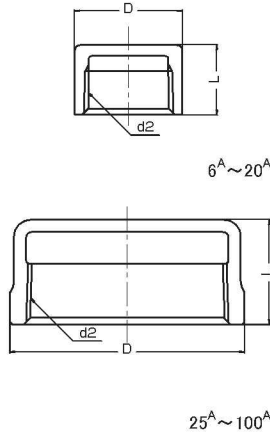


形状・寸法

■ キャップ


C

304(SUS 304 または SCS 13A)
316(SUS 316 または SUS F316)

呼び径		ねじ	寸法 (mm)		304 在庫	316 在庫
A (mm)	B (inch)		d2	D		
6	1/8	Rc1/8	15	15	●	—
8	1/4	Rc1/4	19	17	●	●
10	3/8	Rc3/8	22	18.5	●	●
15	1/2	Rc1/2	28	21.5	●	●
20	3/4	Rc3/4	32	25	●	●
25	1	Rc1	42	27.5	●	●
32	1 1/4	Rc1 1/4	51.5	30	●	—
40	1 1/2	Rc1 1/2	57.5	30.5	●	—
50	2	Rc2	70	35	●	—
65	2 1/2	Rc2 1/2	87	39	●	—
80	3	Rc3	102	42	●	—
100	4	Rc4	129	48	●	—

■ ブッシング

B

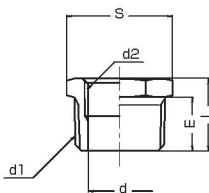304(SUS 304, SUS F304 または SCS 13A)
316(SUS 316 または SUS F316)

呼び径		ねじ		寸法 (mm)						304 在庫	316 在庫
A (mm)	B (inch)	d1	d2	L	E	d	S				
							六角	八角	十角		
8×6	1/4×1/8	R1/4	Rc1/8	17	12	8	14	—	—	●	●
10×6	3/8×1/8	R3/8	Rc1/8	18	13	8	17	—	—	●	●
10×8	3/8×1/4	R3/8	Rc1/4	18	13	11	17	—	—	●	●
15×6	1/2×1/8	R1/2	Rc1/8	21	16	8	22	—	—	●	—
15×8	1/2×1/4	R1/2	Rc1/4	21	16	11	22	—	—	●	●
15×10	1/2×3/8	R1/2	Rc3/8	21	16	14	22	—	—	●	●
20×8	3/4×1/4	R3/4	Rc1/4	24	18	11	—	27	—	●	—
20×10	3/4×3/8	R3/4	Rc3/8	24	18	14	—	27	—	●	●
20×15	3/4×1/2	R3/4	Rc1/2	24	18	18	—	27	—	●	●
25×8	1×1/4	R1	Rc1/4	27	20	11	—	34	—	●	—
25×10	1×3/8	R1	Rc3/8	27	20	14	—	34	—	●	—
25×15	1×1/2	R1	Rc1/2	27	20	20	—	35	—	●	●
25×20	1×3/4	R1	Rc3/4	27	20	26	—	35	—	●	●
32×15	1 1/4×1/2	R1 1/4	Rc1/2	32.5	23.5	33	—	43	—	●	—
32×20	1 1/4×3/4	R1 1/4	Rc3/4	32.5	23.5	33	—	43	—	●	—
32×25	1 1/4×1	R1 1/4	Rc1	32.5	23.5	33	—	43	—	●	—
40×15	1 1/2×1/2	R1 1/2	Rc1/2	33.5	23.5	39	—	49	—	●	—
40×20	1 1/2×3/4	R1 1/2	Rc3/4	33.5	23.5	39	—	49	—	●	—
40×25	1 1/2×1	R1 1/2	Rc1	33.5	23.5	39	—	49	—	●	—
40×32	1 1/2×1 1/4	R1 1/2	Rc1 1/4	33.5	23.5	39	—	49	—	●	—
50×20	2×3/4	R2	Rc3/4	37.5	26.5	50	—	61	—	●	—
50×25	2×1	R2	Rc1	37.5	26.5	50	—	61	—	●	—
50×32	2×1 1/4	R2	Rc1 1/4	37.5	26.5	50	—	61	—	●	—
50×40	2×1 1/2	R2	Rc1 1/2	37.5	26.5	50	—	61	—	●	—
65×40	2 1/2×1 1/2	R2 1/2	Rc1 1/2	39	28	62	—	—	80	●	—
65×50	2 1/2×2	R2 1/2	Rc2	39	28	62	—	—	80	●	—
80×40	3×1 1/2	R3	Rc1 1/2	44	32	74	—	—	95	●	—
80×50	3×2	R3	Rc2	44	32	74	—	—	95	●	—
80×65	3×2 1/2	R3	Rc2 1/2	44	32	75	—	—	95	●	—