


ST-A Series (Pitch 7.62mm integrated PCB terminal block)


Highly reliable integrated PCB terminal block

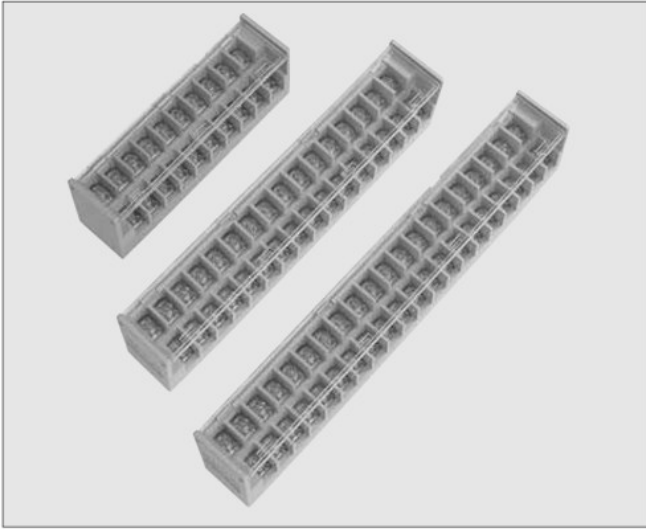

■ Features

- 2 tiered PCB type terminal block of 20, 34, 40 pole most frequently used by users
- PC cover(window) is applied, the appearance looks great, and the user's arbitrary symbol can be inserted
- Both Y and O terminals are applicable

■ Model configuration

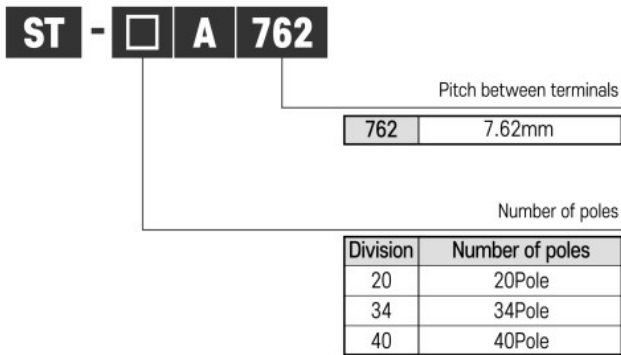


■ Specification

Rated voltage	250V, 10A
Withstand voltage	AC2,000V/for 1 minute
Insulation resistance	DC500V, 100MΩ or more
Suitable wire	AWG22~16 (1.5mm/MAX)
T/B blot	M3 × 6L
Tightening torque	0.8N·m (8Kgf·cm)


■ Material

External case	NORYL, UL94-V0
Cover	Pdycarbonate, transparent
T/B bolt	Steel, Nickel plated
Pin	Brass, Tin plated

■ Dimension

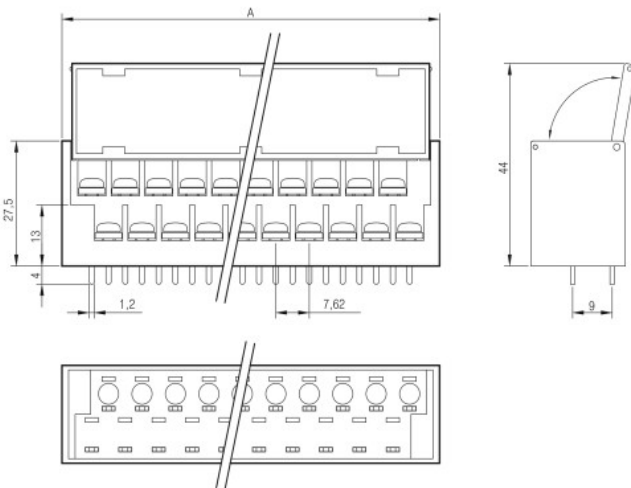

■ PCB mounting holes (top view)

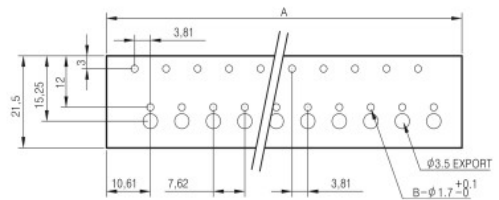

Model	A	Pole
ST-20A-762	85.5mm±0.5	20
ST-34A-762	139.5mm±0.5	34
ST-40A-762	161.5mm±0.5	40

※ For the number strip (name plate), download the CAD (.dwg) file from the data room of our website (en.iolink.co.kr) and use it.