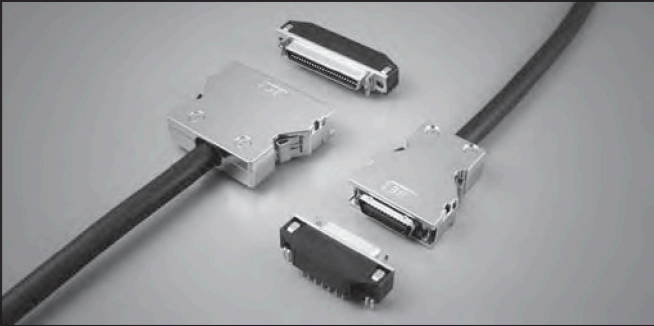
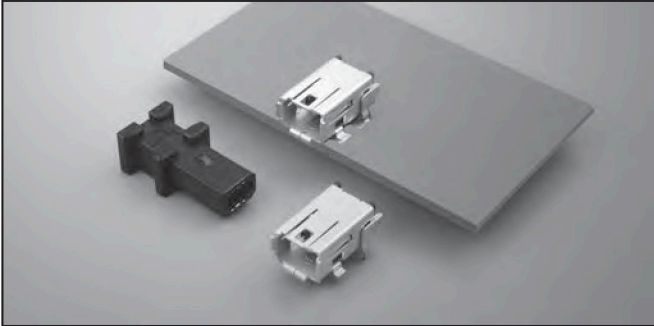
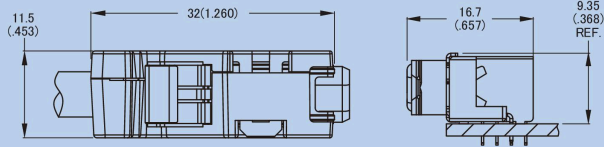
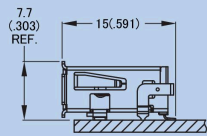
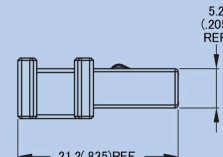


角型コネクタ・RECTANGULAR CONNECTORS

| DF02 | DZ02 |
|---|--|
| 1.27 mm (.050inch) Pitch • EMI Shielded | 0.635 mm (.025 inch) Pitch • EMI Shielded |
| 基板対電線 PCB to Cable | 基板対電線 PCB to Cable |
| 半田 / 圧接 Solder / IDC | — |
| 半田 (スルーホール) Solder (Through-hole) | 半田 (SMT) Solder (Surface mount) |
|  |  |
|  | <p>Receptacle</p>  <p>Short-circuit plug</p>  |
| 14, 20, 26, 36, 50 | 8 |
| Straight | — |
| Right-angle | Right-angle |
| 1.6 mm (.063 inch) | — |
| Solder : # 24AWG max. IDC : # 28 to # 30AWG | — |
| 0.5Amps | 0.5Amps |
| 500 VACrms (1 minute) | 250 VACrms (1 minute) (Individual connector) |
| 100 megohms min. | 500 megohms min. (Individual connector) |
| 35 milliohms max. | Receptacle : 40 milliohms max. Short - circuit plug : 80 milliohms max. |
| - 20 °C to + 80 °C | - 40 °C to + 85 °C |
| Gold plating | Gold plating |
| | <ul style="list-style-type: none"> ● IEC61508における製品規格 IEC /EN61800-5-2適用レセプタクルとして使用可 ● It can be used as a receptacle compatible with the product standard IEC /EN 61800 - 5 - 2 of the international standard IEC 61508 |