
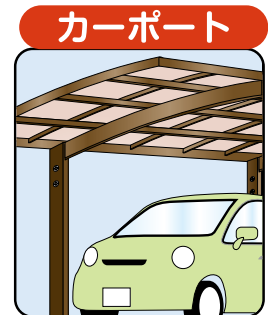
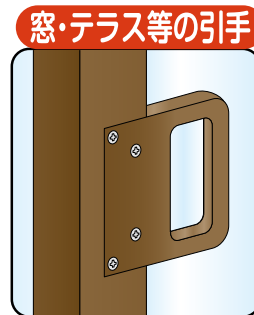
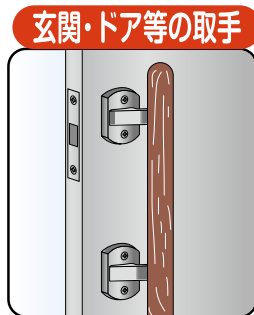
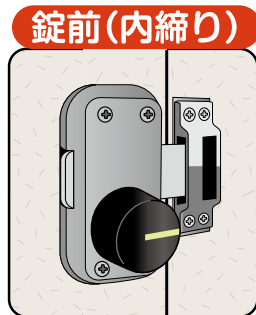
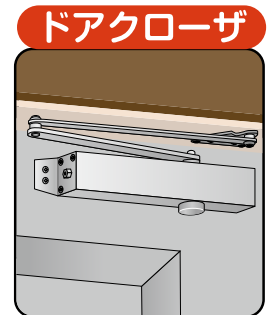
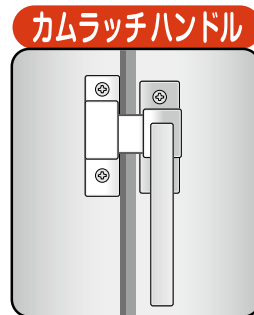
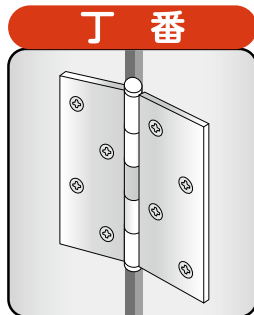
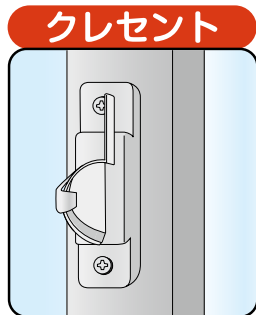
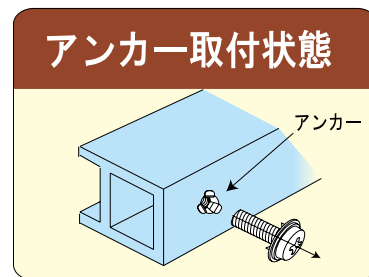


特長

- ねじがゆるくなったときの補強
- 取付専用工具不要
- 薄板専用
- 框奥行寸法 12mm 以上

用途

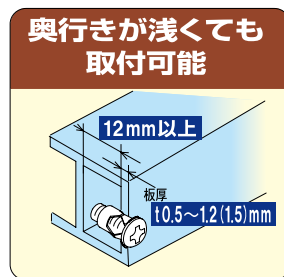

仕様

アンカー材質: SUS304

適合材質
アルミ・スチール
 ※樹脂サッシは不可
薄板用
 t 0.5~1.2 (1.5) mm

品番	ネジ径	框奥行寸法	框厚有効 (t)	下穴寸法	引張強度 (kgf)
KA3-10	M3	12mm 以上	0.5~1.2mm	6.2φ	15 (MAX30)
KA4-10	M4	12mm 以上	0.5~1.5mm	6.2φ	40 (MAX80)
KA5-12	M5	12mm 以上	0.5~1.5mm	7.3φ	60 (MAX100)