



# ゲリルノブ GK, GKF

Grille Knobs GK, GKF

RoHS指令適合品

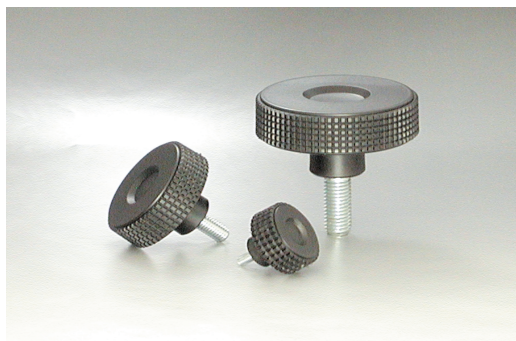


GK

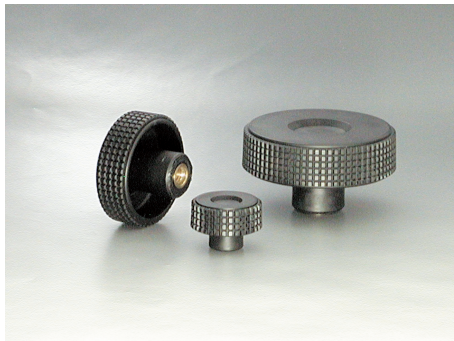

GKF

材 ノブ knob : 艶消し黒色ナイロン樹脂PA6  
Nylon resin Black  
ネジ screw : 鋼材SUM22L・三価クロメート  
Steel Trivalent Chromate

材 ノブ knob : 艶消し黒色ナイロン樹脂PA6  
Nylon resin Black  
ネジ screw : 黄銅C3604B brass

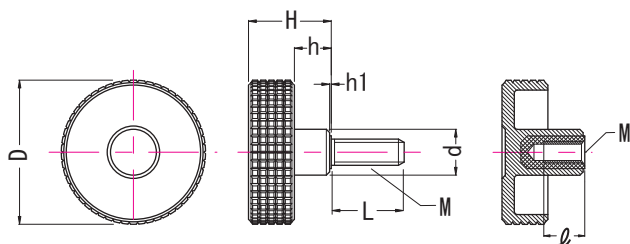

Unit : mm

品番	D	M	L	d	H	h	h1	(g)
GK-30×10	31	M 5×P0.8	10	15	22 (24)	9.0 (11.5)	0.3	13
GK-30×20			20					14
GK-40×10	40 (39.5)	M 6×P1.0	10	17	24 (26.5)	11.0 (12.5)		18
GK-40×20			20					20
GK-50×16	50	M 8×P1.25	16	20	30 (33)	13.5 (16)		36
GK-50×30			30					38
GK-60×20	60 (61)	M10×P1.5	20	23	35 (39)	15.0 (18.5)		58
GK-60×50			50					73
GK-70×30	69	M12×P1.75	30	24	38 (42)	18.5 (20.5)		90
GK-70×50			50					105

Unit : mm

品番	D	M	φ	d	H	h	h1	(g)
GKF-30	31	M 5×P0.8	10	15	22 (24)	9.0 (11.5)	0.3	12
GKF-40	40 (39.5)	M 6×P1.0	12	17	24 (26.5)	11.0 (12.5)		22
GKF-50	50	M 8×P1.25	13	20	30 (33)	13.5 (16)		32
GKF-60	60 (61)	M10×P1.5	17	23	35 (39)	15.0 (18.5)		50
GKF-70	69	M12×P1.75	20	24	38 (42)	18.5 (20.5)		70

注意事項 使用温度 max80°C min-20°C

新ロット製作品は( )内の寸法になります。お問い合わせ下さい。tel 052-732-1141