



Dimensions (mm)

Plug UP

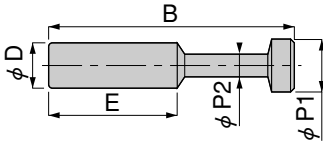

Model	Applicable fitting diameter ϕ D	B	E	ϕ P1	ϕ P2	Mass (g) [oz.]
UP4	4	27.5	15	5	3	0.3 [0.011]
UP6	6	32.5	17	7	3	0.7 [0.025]
UP8	8	36.5	18.1	9	4	1.1 [0.039]
UP10	10	42	20.2	11	5	1.9 [0.067]
UP12	12	44	23.4	13	6	2.4 [0.085]
UP16	16	46	24.1	17	8	4.2 [0.148]

Cap UC

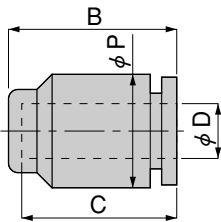

Model	Tube outer diameter ϕ D	B	ϕ P	C	Mass (g) [oz.]
UC4	4	16.4	10	14.9	2.4 [0.085]
UC6	6	18.5	12.5	17	3.3 [0.116]
UC8	8	19.9	14.5	18.4	4.7 [0.166]
UC10	10	22.3	17.5	20.7	7.8 [0.275]
UC12	12	24.9	21	23.4	12 [0.42]