


VSC

ⓑ VA-3

Needle Valve (Type S-C)
ニードルバルブ (ねじ込み式)



Cd ≤ 75ppm

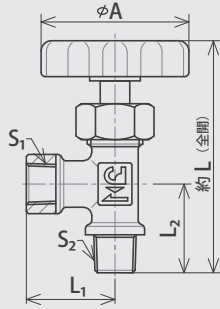

品番	旧品番	呼称 S ₁ × S ₂	対辺寸法	適用ねじ		寸法情報				
				S ₁ (Rc)	S ₂ (R)	φA	L ₁	L ₂	約L	最小穴径
VSC 81818	MV-701	1/8 × 1/8	12	1/8	1/8	35	21.0	21.0	59.0	3.5
VSC 82828	MV-702	1/4 × 1/4	16	1/4	1/4	35	26.0	26.0	70.0	5.0
VSC 83838	MV-703	3/8 × 3/8	17	3/8	3/8	45	31.0	29.0	80.0	6.5
VSC 84848	MV-704	1/2 × 1/2	23	1/2	1/2	55	36.0	36.0	105	9.0


VSD

ⓑ VA-4

Needle Valve (Type S-D)
ニードルバルブ (ねじ込み式)



Cd ≤ 75ppm

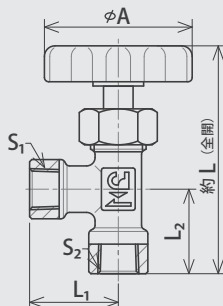

品番	旧品番	呼称 S ₁ × S ₂	対辺寸法	適用ねじ		寸法情報				
				S ₁ (Rc)	S ₂ (Rc)	φA	L ₁	L ₂	約L	最小穴径
VSD 81818	MV-801	1/8 × 1/8	12	1/8	1/8	35	21.0	20.0	58.0	3.5
VSD 82828	MV-802	1/4 × 1/4	16	1/4	1/4	35	26.0	25.0	69.0	5.0
VSD 83838	MV-803	3/8 × 3/8	17	3/8	3/8	45	31.0	27.0	78.0	6.5
VSD 84848		1/2 × 1/2	23	1/2	1/2	55	36.0	34.0	103	9.0