


# Control Boxes

Metal control boxes (closed type)

BXA Series

Steel plate protection structure: IP40, Paint color: 5Y 7/1

Application		Type name	External dimensions (mm)			General mass (kg)
			A	B	C	
Without holes	For 1 point	<b>BXA001</b>	80	100	92	0.30
	For 2 points	<b>BXA002</b>	80	150	92	0.39
	For 3 points	<b>BXA003</b>	80	200	92	0.49
	For 4 points	<b>BXA004</b>	80	250	92	0.58
	For 6 points	<b>BXA006</b>	160	200	92	0.96
With hole For $\phi 16$	For 1 point	<b>BXA161</b>	80	100	92	0.30
	For 2 points	<b>BXA162</b>	80	150	92	0.39
	For 3 points	<b>BXA163</b>	80	200	92	0.49
	For 4 points	<b>BXA164</b>	80	250	92	0.58
	For 6 points	<b>BXA166</b>	160	200	92	0.96
With hole For $\phi 22$	For 1 point	<b>BXA221</b>	80	100	92	0.30
	For 2 points	<b>BXA222</b>	80	150	92	0.39
	For 3 points	<b>BXA223</b>	80	200	92	0.49
	For 4 points	<b>BXA224</b>	80	250	92	0.58
	For 6 points	<b>BXA226</b>	160	200	92	0.96
With hole For $\phi 25$	For 1 point	<b>BXA251</b>	80	100	92	0.30
	For 2 points	<b>BXA252</b>	80	150	92	0.39
	For 3 points	<b>BXA253</b>	80	200	92	0.49
	For 4 points	<b>BXA254</b>	80	250	92	0.58
	For 6 points	<b>BXA256</b>	160	200	92	0.96
With hole For $\phi 30$	For 1 point	<b>BXA301</b>	80	100	92	0.30
	For 2 points	<b>BXA302</b>	80	150	92	0.39
	For 3 points	<b>BXA303</b>	80	200	92	0.49
	For 4 points	<b>BXA304</b>	80	250	92	0.58
	For 6 points	<b>BXA306</b>	160	200	92	0.96

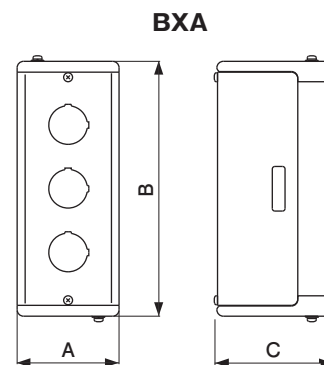

Control Switches

Pilot Lamps

Control Boxes