

## 0314 KSS MARKER TIE




UNIT : mm



| Item No. | Length |        | W   | Max.Bundle Dia. | Marking pad | Min LoopTensile Strength |     | Packing |
|----------|--------|--------|-----|-----------------|-------------|--------------------------|-----|---------|
|          | mm     | inch   |     |                 |             | lbs                      | kgs |         |
| PMT-150  | 160    | 6 1/4" | 5.0 | 25              | 9.2 X 30    | 4                        | 2   | 100pcs  |

- Material : PE
- Color: Natural
- Put the marking paper chip into marker box.

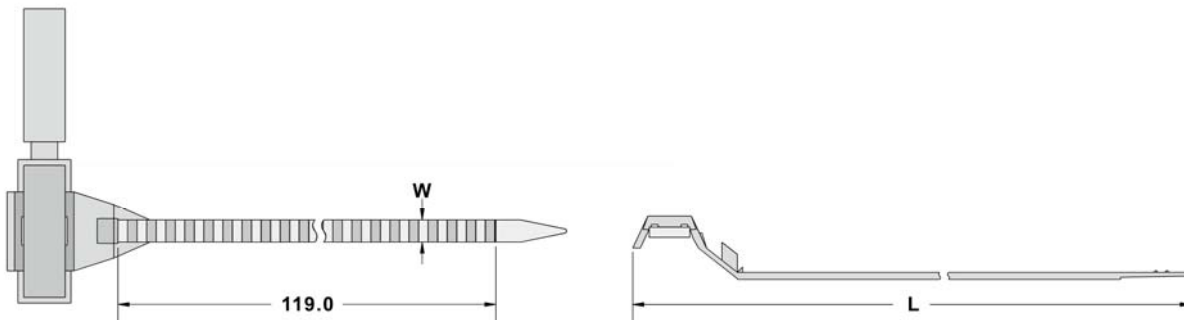

## 0315 KSS RELEASABLE CABLE TIE



UNIT : mm



| Item No.            |         | Length |           | W   | Max.Bundle Dia. | Min LoopTensile Strength |     | Packing |
|---------------------|---------|--------|-----------|-----|-----------------|--------------------------|-----|---------|
| Black               | Natural | mm     | inch      |     |                 | lbs                      | kgs |         |
| HV-125BK            | HV-125  | 125    | 4 15/16"  | 7.6 | 30              | 50                       | 22  | 100 pcs |
| HV-150BK            | HV-150  | 150    | 6"        | 7.6 | 35              | 50                       | 22  |         |
| HV-200BK            | HV-200  | 203    | 8"        | 7.6 | 50              | 50                       | 22  |         |
| HV-250BK            | HV-250  | 250    | 10"       | 7.6 | 65              | 50                       | 22  |         |
| HV-300BK            | HV-300  | 300    | 11 7/8"   | 7.6 | 80              | 50                       | 22  |         |
| <b>NEW</b> HV-500BK |         | 500    | 19 11/16" | 8.5 | 145             | 75                       | 34  |         |

- Material: UL approved Nylon 66, 94V-2
- Color: Black , Natural
- Easily assembled by hand or with pliers, remain securely locked until intentionally released by operating the finger catch.

