
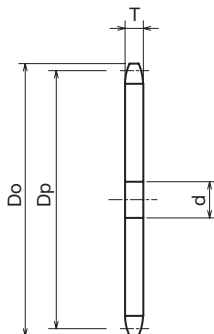


Order No. Example

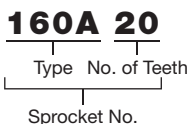

- Chain No.160
- Chain Pitch (P)50.80mm
- Roller Link Inner Width (W)31.75mm
- Roller Outside Diameter (Dr)28.58mm
- Tooth Width (T)29.4 mm

 Common Steel

Type	No. of Teeth	Outer Diameter Do	Pitch Diameter Dp	Shaft Hole Diameter d		Weight kg	¥	Semi-F ¥
				Prepared Hole	Minimum			
160A	10	187	164.39	26	27	4.85		
	11	204	180.31	26	27	5.85		
	12	220	196.28	26	27	6.90		
	13	237	212.27	26	27	8.10		
	14	253	228.30	26	27	9.40		
	15	269	244.33	30	31	10.80		
	16	286	260.39	30	31	12.25		
	17	302	276.46	30	31	13.80		
	18	319	292.55	30	31	15.50		
	19	335	308.64	30	31	17.20		
	20	351	324.74	30	31	19.00		
	21	368	340.84	30	31	21.00		
	22	384	356.96	35	36	23.00		
	23	400	373.07	35	36	25.10		
	24	416	389.19	35	36	27.40		
	25	433	405.32	35	36	29.70		
	26	449	421.45	35	36	32.10		
	28	481	453.72	35	36	37.20		
	30	514	485.99	35	36	42.70		
	32	546	518.28	35	36	48.70		
	35	595	566.71	35	36	58.10		
	38	644	615.17	35	36	68.50		
	40	676	647.47	35	36	75.10		
	45	757	728.25	35	36	96.00		
	48	806	776.72	35	36	109.00		
	50	838	809.04	35	36	118.50		
	54	903	873.68	35	36	138.20		
	60	1,000	970.65	35	36	170.00		



Order Method

Sprocket No. and Quantity



Weight limit for single product packaging

* Goods for which the weight of a single item exceeds 30kg With Sagawa Express/Yamato Transport, products cannot be shipped at any time.



Postage

Same-day shipping



Guide

* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/taps, etc., depending on your request, please contact our company's sales office for details.

* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.