


 
# SUS2062B



## SUS Standard Stainless Steel Double Pitch Sprocket for R Rollers B-type

### ● Order No. Example

**SUS 2062B 12**

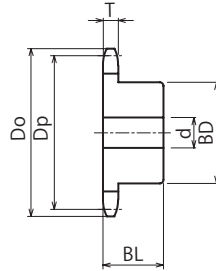

- Chain ..... No.C2062H
- Chain Pitch ..... (P)38.10mm
- Roller Link Inner Width ..... (W)12.70mm
- Roller Outside Diameter ..... (Dr)22.23mm
- Tooth Width ..... (T)11.7 mm

**m** Stainless Steel **GB** 304

| Type             | Action No. of Teeth | Outer Diameter Do | Pitch Diameter Dp | Shaft Hole Diameter d |         |         | Boss Diameter BD | Boss Length BL | Shape                | Weight kg | ¥ | Semi-F ¥ |
|------------------|---------------------|-------------------|-------------------|-----------------------|---------|---------|------------------|----------------|----------------------|-----------|---|----------|
|                  |                     |                   |                   | Prepared Holes        | Minimum | Maximum |                  |                |                      |           |   |          |
| <b>SUS 2062B</b> | 10                  | 140               | 123.29            | 23                    | 24      | 55      | 83               | 45             | Ground Specification | 2.50      |   |          |
|                  | 11                  | 153               | 135.23            | 25                    | 26      | 55      | 83               | 45             |                      | 2.60      |   |          |
|                  | 12                  | 165               | 147.21            | 25                    | 26      | 55      | 83               | 45             |                      | 2.80      |   |          |
|                  | 13                  | 177               | 159.20            | 25                    | 26      | 55      | 83               | 45             |                      | 3.10      |   |          |



Order Method

Sprocket No. and Quantity



Postage

Same-day shipping



Guide

\* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.

\* Please refer to P24 to P33 for the Semi-F Series <Complete Product> order method.