

 
# Super Torque Timing Pulley S8M <for belt with 15mm width>




# S8M150-type

## Order No. Example

**K 20 S8M150 BF**




(Type)  
**S8M150**  
W: 17  
H: 3.5

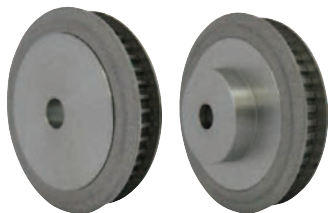

AF

BF

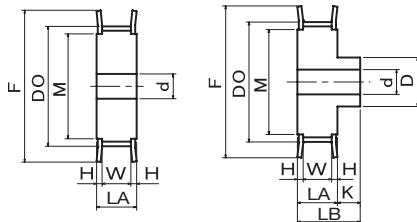

AF Type

BF Type

The KANA Timing Pulley achieves clean transmission thanks to its low noise that comes by way of its excellent timing transmission performance.

Type	No. of Teeth	Shape	Dp	Do	LA	LB	K	D	d		F	M	Compatible Flanges	Pulley Approx. Weight kg	
									min	max				AF	BF
S8M 150	18	AF, BF	45.84	44.46	24	39	15	32	12	20	54	36	KTF-235436	0.23	0.32
	19	AF, BF	48.38	47.01	24	39	15	35	12	22	57	39	KTF-235739	0.26	0.37
	20	AF, BF	50.93	49.56	24	39	15	36	12	22	60	40	KTF-236040	0.29	0.41
	21	AF, BF	53.48	52.10	24	39	15	40	12	24	62	44	KTF-236244	0.33	0.48
	22	AF, BF	56.02	54.65	24	39	15	41	12	25	65	45	KTF-236545	0.37	0.52
	24	AF, BF	61.12	59.74	24	39	15	46	12	28	70	50	KTF-237050	0.45	0.65
	25	AF, BF	63.66	62.29	24	39	15	48	16	29	72	52	KTF-237252	0.49	0.68
	26	AF, BF	66.21	64.84	24	39	15	51	16	30	75	55	KTF-237555	0.52	0.76
	28	AF, BF	71.30	69.93	24	39	15	55	16	34	80	60	KTF-238060	0.61	0.89
	30	AF, BF	76.39	75.02	24	39	15	60	16	36	85	65	KTF-238565	0.72	1.05
	32	AF, BF	81.49	80.12	24	39	15	65	16	38	90	70	KTF-239070	0.83	1.22
	34	AF, BF	86.58	85.21	24	39	15	70	16	42	95	75	KTF-239575	0.95	1.40
	36	AF, BF	91.67	90.30	24	39	15	75	16	45	100	80	KTF-2310080	1.08	1.60
	38	AF, BF	96.77	95.39	24	39	15	80	20	48	105	85	KTF-2310585	1.21	1.77
	40	AF, BF	101.86	100.49	24	39	15	85	20	50	110	90	KTF-2311090	1.32	1.99
	44	AF, BF	112.05	110.67	24	44	20	90	20	56	121	101	KTF-23121101	1.62	2.62
	48	AF, BF	122.23	120.86	24	44	20	100	20	62	131	111	KTF-23131111	1.96	3.20
	50	AF, BF	127.32	125.95	24	44	20	100	20	62	136	116	KTF-23136116	2.15	3.38
	60	AF, BF	152.79	151.42	24	44	20	100	20	62	161	141	KTF-23161141	3.17	4.40



Timing Pulley No. and Quantity



Guide

\* Since we also manufacture sizes other than those in the catalog, and machine shaft holes/keys/taps, etc., depending on your request, please contact our company's sales office for details.



Postage

Same-day shipping



Precautions

\* The prepared hole diameter is finished at the minimum diameter H7. Comes with a flange.