


Premium *STICKON DISC ROLL*

with improved backing paper

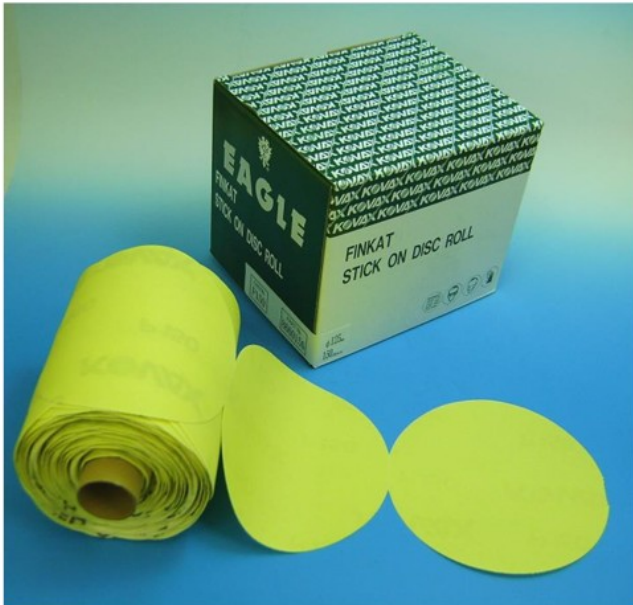

GCSMM-DR P150 125mm dia. P-0



GCLMM-DR P400 152mm dia. P-0

Kovax new **STICKON DISC ROLLS** GCLMM-DR/ GCSMM-DR/GDSMM-DR utilize special flexible bonding technology that will effectively reduce scratches and increase cutting power. These high performance disc rolls with tough backing paper last long and produce superb finishes that will satisfy the most demanding requirements.

Advantages :

- Enhanced Initial Cutting Power
- Extra Long Paper Life with Tough Backing and Anti-Clogging Agent
- Superb Finish

Specifications :

Code	Part No.	Available Grit	Size	Hole type
GDSMM-DR (P60-P100)	866-	P60, P80, P100, P120, P150, P180, P220, P240, P320, P400 & P600	5"(125mm dia.)	P-0 (without hole)
GCSMM-DR (P120-P220)			6"(152mm dia.)	P-0 (without hole)
GCLMM-DR (P240-P600)	867-			

Not all items and grits are available in all markets. Please ask your agent in your market for the details. Other sizes, shapes and hole types may be available upon request.

Kovax Corporation 29-9, Minami Ikebukuro 2-chome, Toshima-ku, Tokyo, Japan
Tel.(81) 3 5960 1621 Fax.(81) 3 5960 1623 Email: intl@kovax.com

Kovax Europe BV. Bedrijvenpark Twente 49 7602 KC Almelo, The Netherlands
Tel.(31)53 434 3131 Fax:(31) 53 430 4900 Email: info@kovax.nl

Kovax Deutschland GmbH Am Königsweg 17, D-48599 Gronau-Epe, Germany
Tel:(49) 4122 47719 Fax:(49)4122 47725 Email: info@kovax.de

KOVAX
© 2014 Kovax Corporation