


0.020(0.50) Test Centers G026

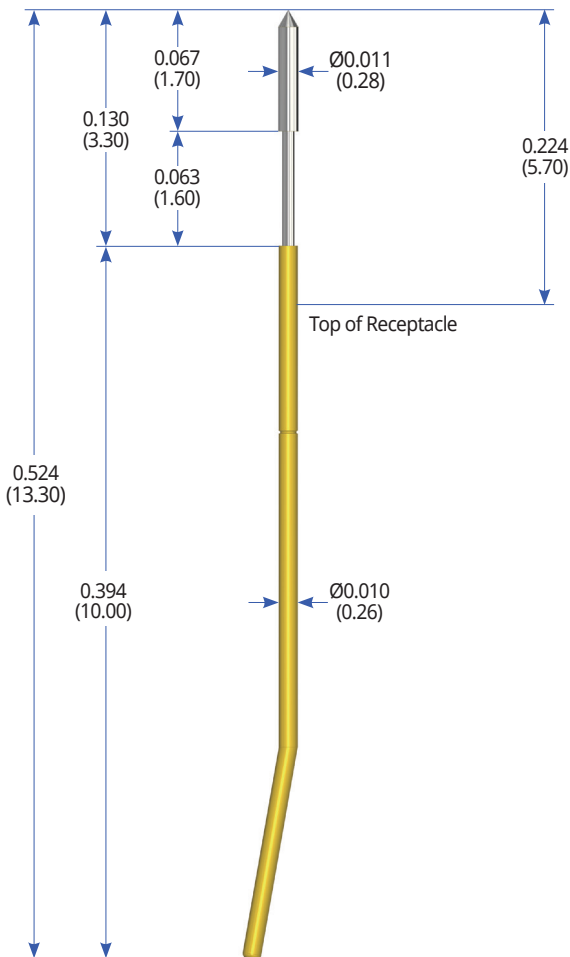

Unit : inch(mm)



Probe Specifications

Electrical(Static Conditions)

- Current Rating : 0.5amps
- Probe Resistance : Less than 250mΩ

Materials and Finishes


- Plunger : Hardened Steel, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±30%	Oz(Grams)
Recommended Travel	Full Travel
0.028(0.7mm)	0.059(1.5mm)
0.635(18)	0.917(26)

Receptacle Specifications

- Housing : Phosphor Bronze or Brass, Gold Plated

G026W-R1 No Termination Receptacle

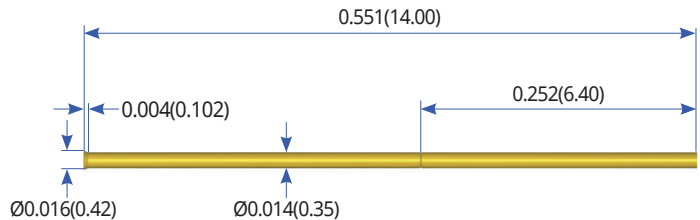

G026SW-R1 Preattached Wire Receptacle

