


0.022(0.55) Test Centers G030

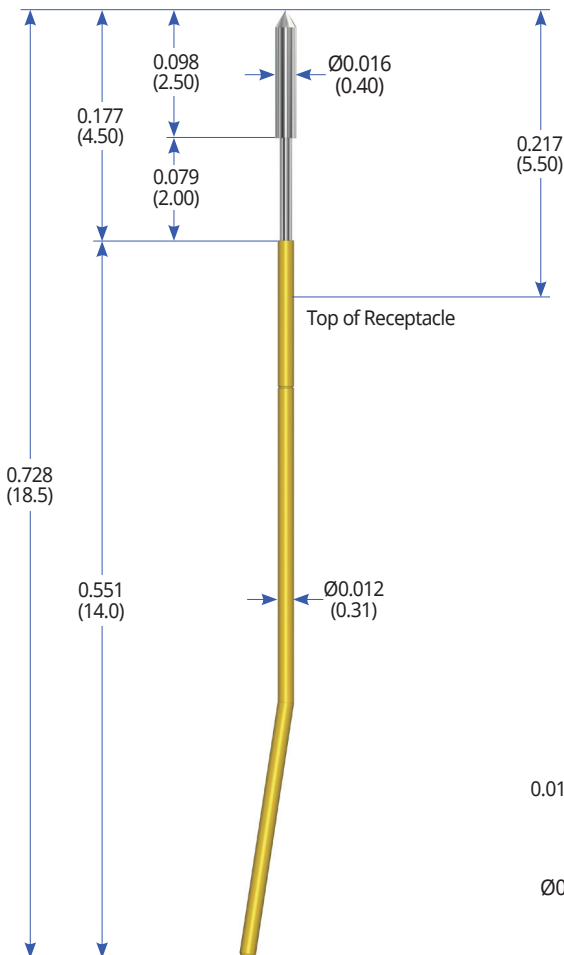

Unit : inch(mm)



Probe Specifications

Electrical(Static Conditions)

- Current Rating : 0.5amps
- Probe Resistance : Less than 150mΩ

Materials and Finishes


- Plunger : Hardened Steel, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±30%	Oz(Grams)
Recommended Travel 0.059(1.5mm)	Full Travel 0.079(2.0mm)
0.952(27)	1.129(32)

Receptacle Specifications

- Housing : Phosphor Bronze or Brass, Gold Plated

G030TW No Termination Receptacle

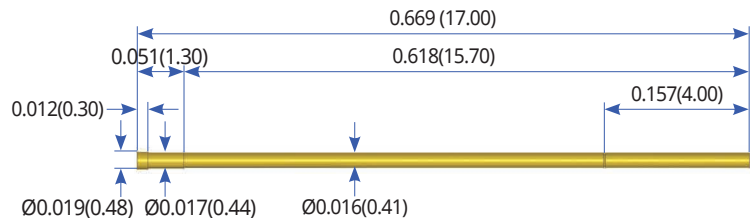

G030SW Preattached Wire Receptacle

