



0.030(0.80) Test Centers G042

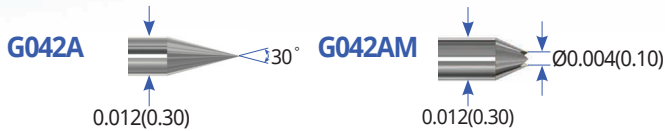

Unit : inch(mm)

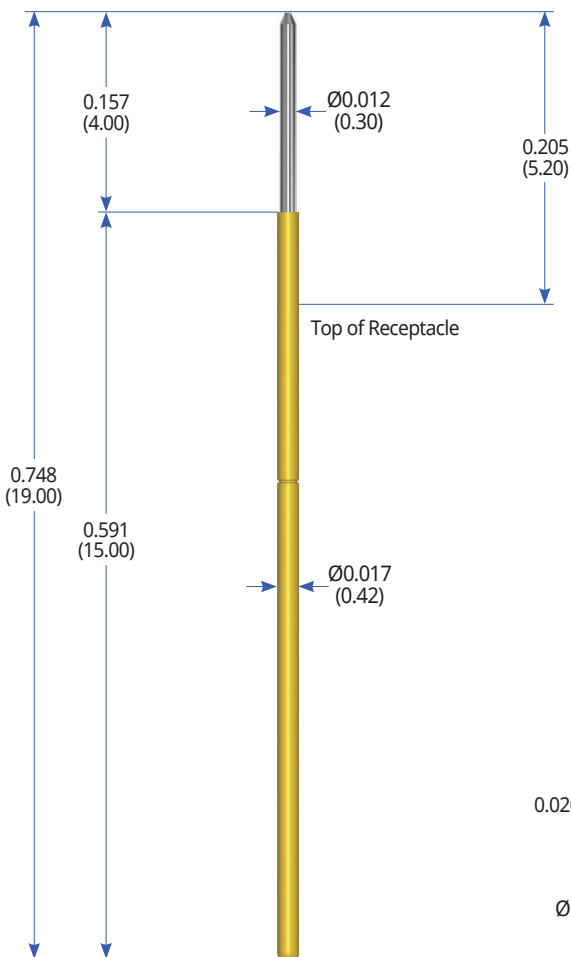

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 0.5amps Continuous
- Probe Resistance : Less than 100mΩ

Materials and Finishes


- Plunger : Hardened Steel, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±30%	Oz(Grams)
Recommended Travel	Full Travel
0.051(1.3mm)	0.079(2.0mm)
1.270(36)	1.516(43)

Receptacle Specifications

- Housing : Phosphor Bronze or Brass, Gold Plated

G042TW No Termination Receptacle

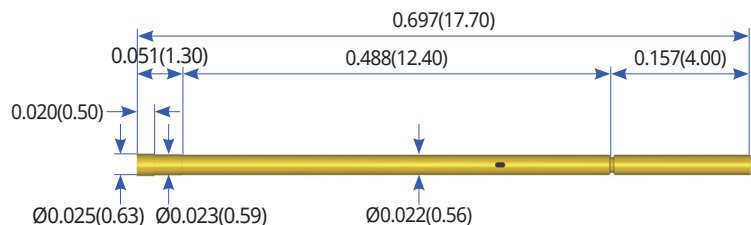

G042SW Preattached Wire Receptacle

