



0.030(0.80) Test Centers G050

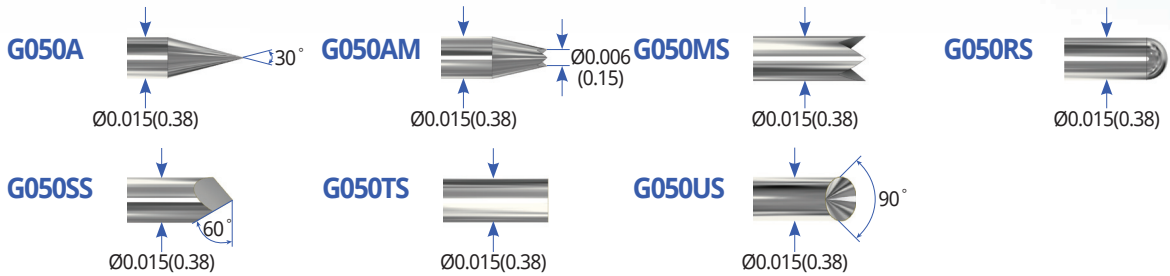

Unit : inch(mm)

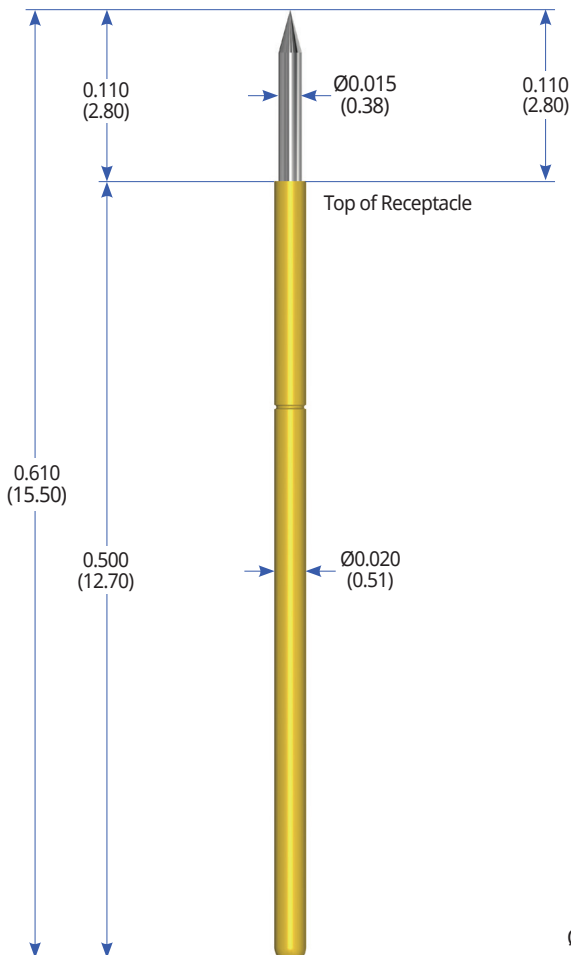

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 2amps
- Probe Resistance : Less than 50mΩ

Materials and Finishes


- Plunger : Hardened Steel, Hardened Beryllium Copper, Palladium Plated(Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.067(1.7mm)	0.098(2.5mm)
1.418(40)	1.827(52)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated

G050TW No Termination Receptacle

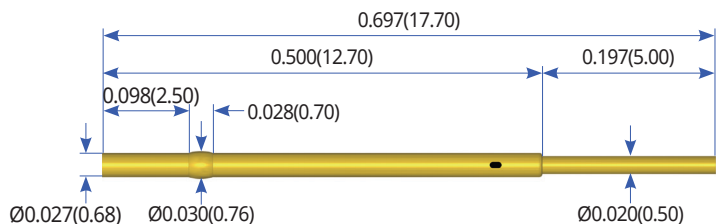

G050SW Preattached Wire Receptacle with Soldering



Wire AWG 30

G050CW Preattached Wire Receptacle with Crimping



Wire AWG 30