



0.050(1.27) Test Centers G070

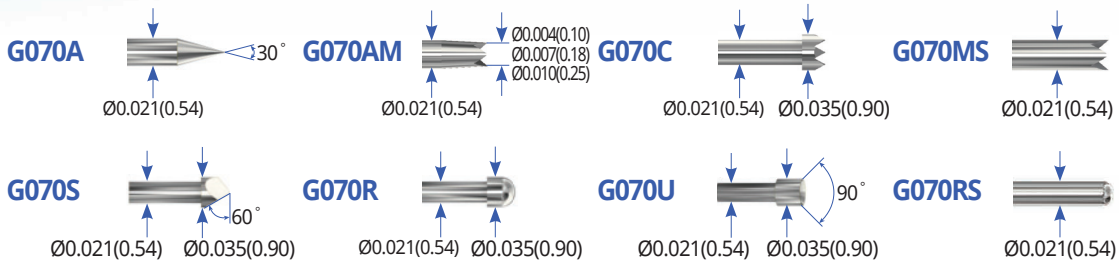

Unit : inch(mm)

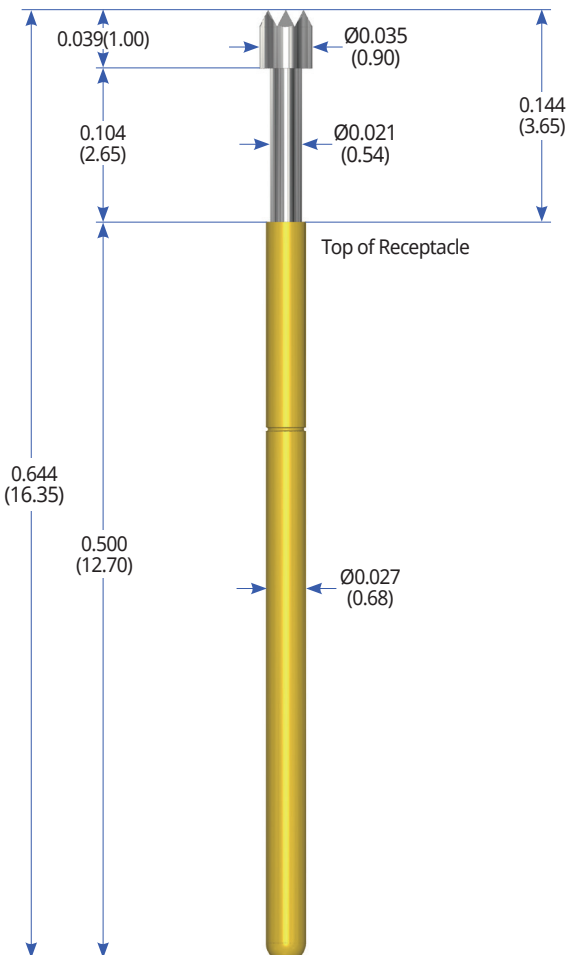

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 3amps
- Probe Resistance : Less than 50mΩ

Materials and Finishes


- Plunger : Hardened Steel, Hardened Beryllium Copper, Palladium Plated(Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.070(1.77mm)	0.104(2.65mm)
2.471(70)	3.177(90)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated

G070TW No Termination Receptacle

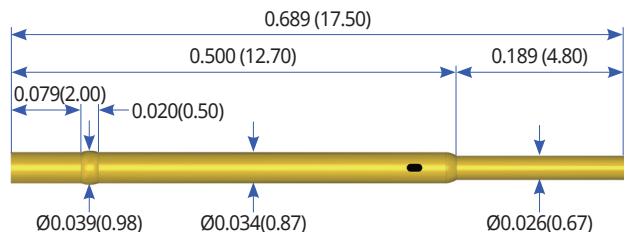

G070CW Preattached Wire Receptacle with Crimping



G070SW Preattached Wire Receptacle with Soldering

