



0.050(1.27) Test Centers G070L

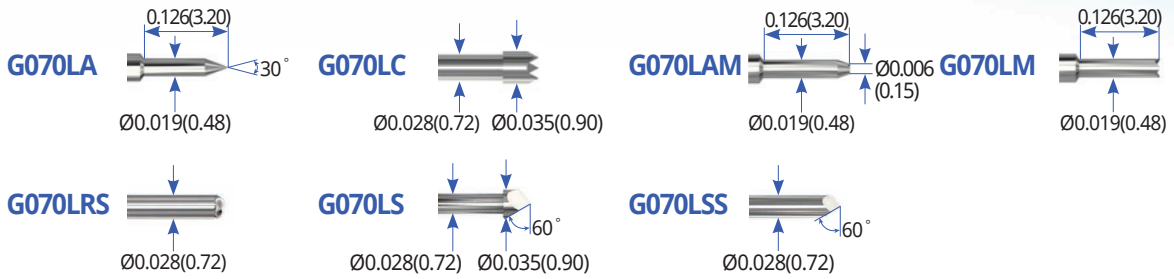

Unit : inch(mm)

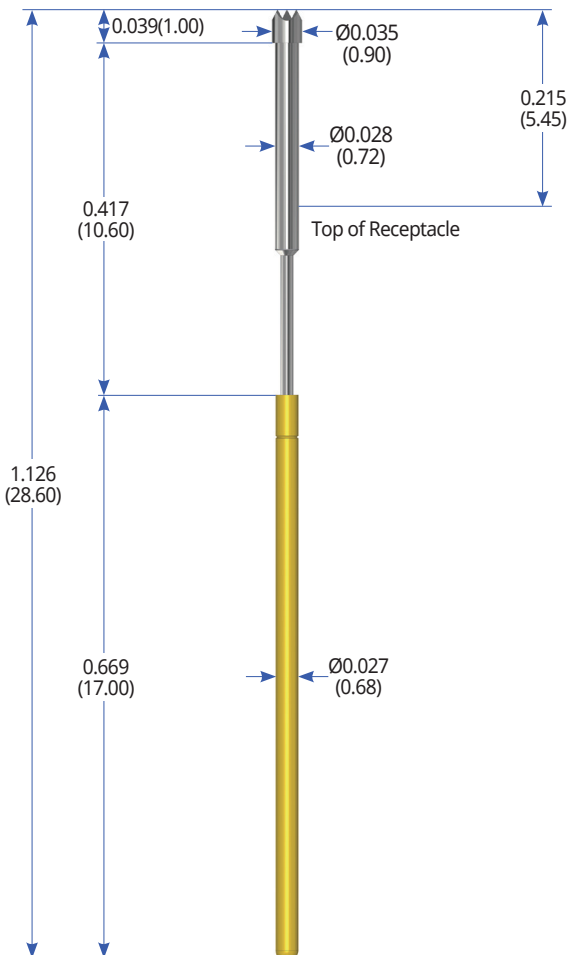

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 3amps
- Probe Resistance : Less than 50mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Brass, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.110(2.8mm)	0.165(4.2mm)
2.469(70)	3.53(100)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated

G070LTW Crimp Style Receptacle

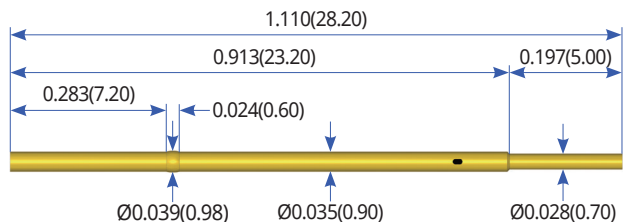

G070LCW Preattached Wire Receptacle

