


0.050(1.27) Test Centers G095

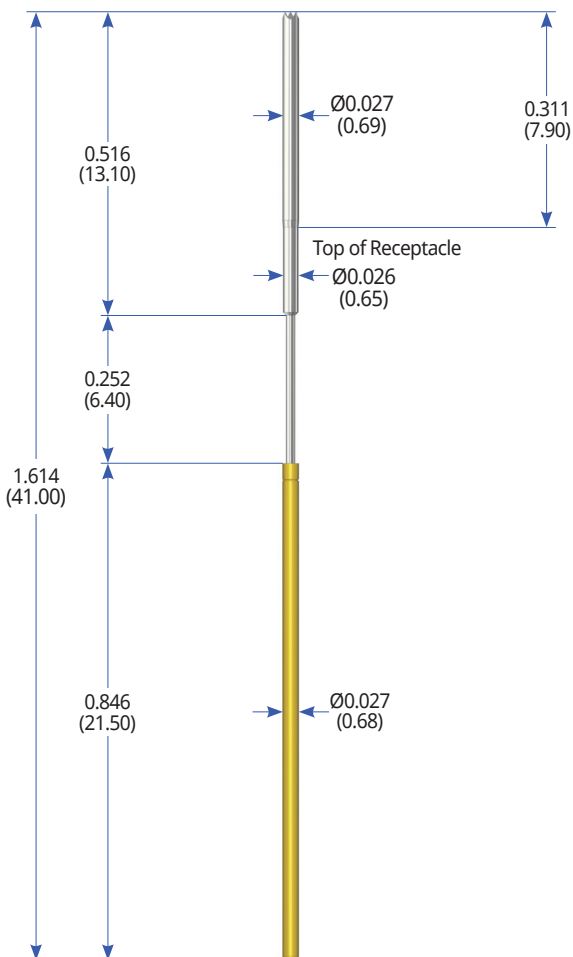

Unit : inch(mm)



Probe Specifications

Electrical(Static Conditions)

- Current Rating : 3amps
- Probe Resistance : Less than 50mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Brass, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.169(4.3mm)	0.252(6.4mm)
2.753(78)	3.883(110)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated

G095TW Crimp Style Receptacle

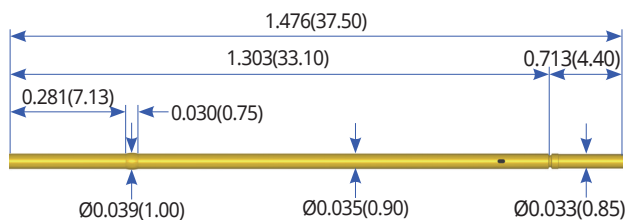

G095SW Preattached Wire Receptacle

