



0.075(1.91) Test Centers G105

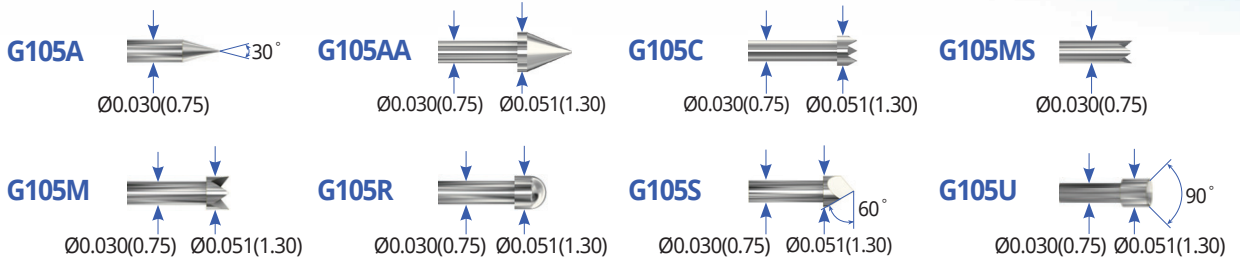

Unit : inch(mm)

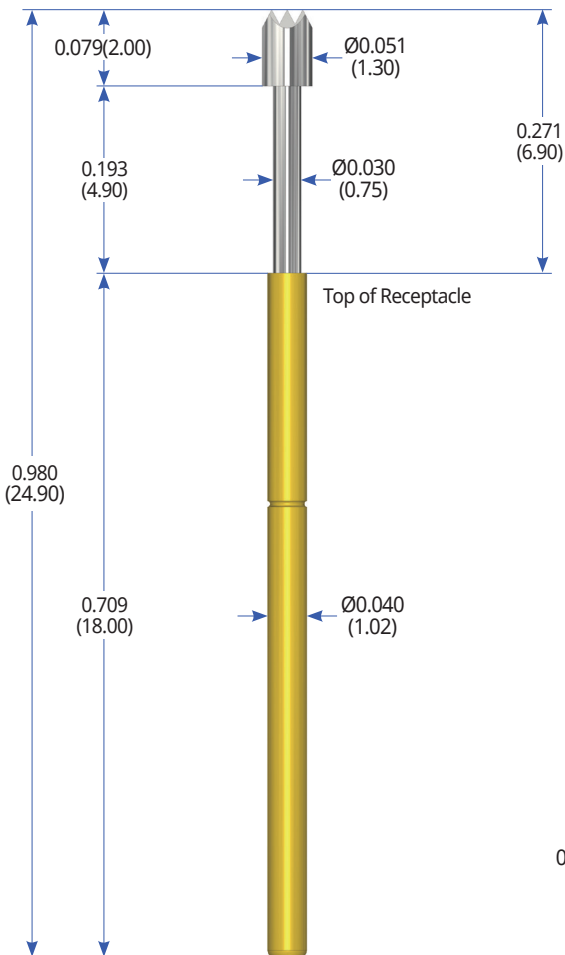

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 6amps
- Probe Resistance : Less than 30mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.130(3.3mm)	0.193(4.9mm)
4.413(125)	6.001(170)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Nickel Plated
- Square Post : Brass, Gold Plated

GS105W-2.3 Wire-Wrap Receptacle

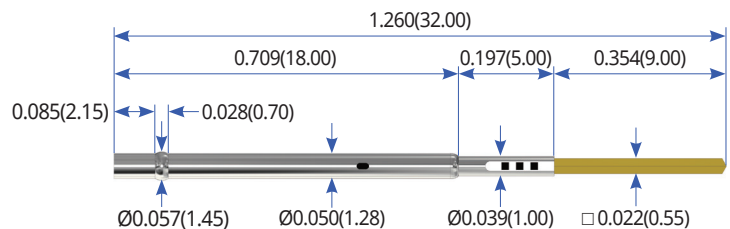

GS105SW-2.3 Solder Cup Receptacle



GS105TW-2.3 Crimp Style Receptacle

