



0.100(2.54) Test Centers GS135

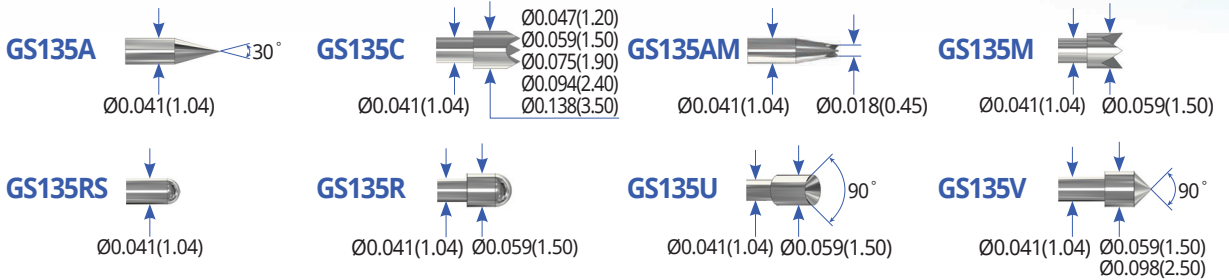

Unit : inch(mm)

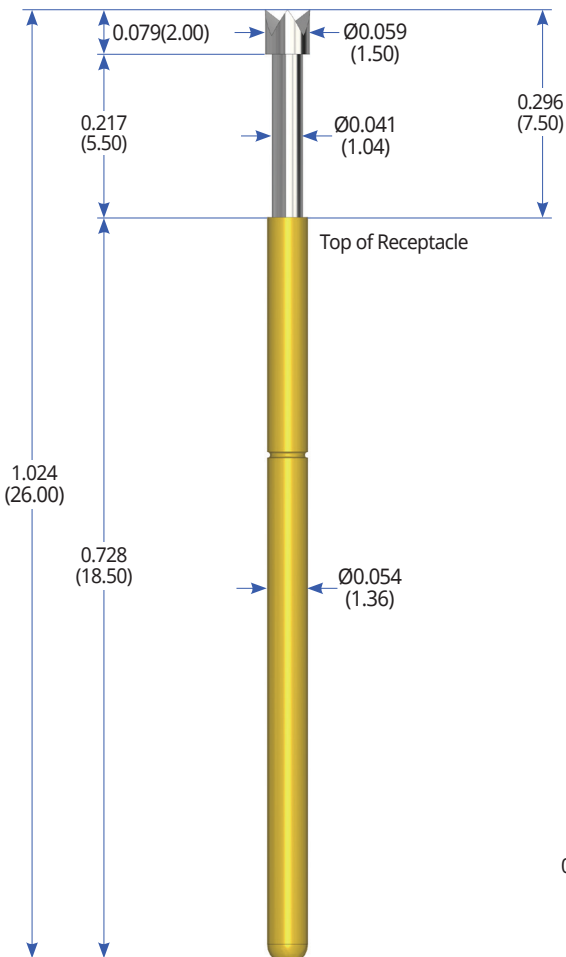

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 6amps
- Probe Resistance : Less than 30mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Brass, Gold Plated
- Spring : Music Wire

| | |
|--------------------|--------------|
| Spring Force ±20% | Oz(Grams) |
| Recommended Travel | Full Travel |
| 0.144(3.67mm) | 0.217(5.5mm) |
| 6.001(170) | 8.119(230) |

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Nickel Plated
- Square Post : Brass, Gold Plated

GS135W-2.3 Wire-Wrap Receptacle

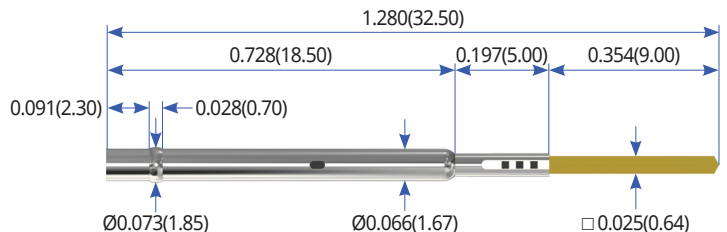

GS135SW-2.3 Solder Cup Receptacle



GS135TW-2.3 Crimp Style Receptacle

