



0.100(2.54) Test Centers G135

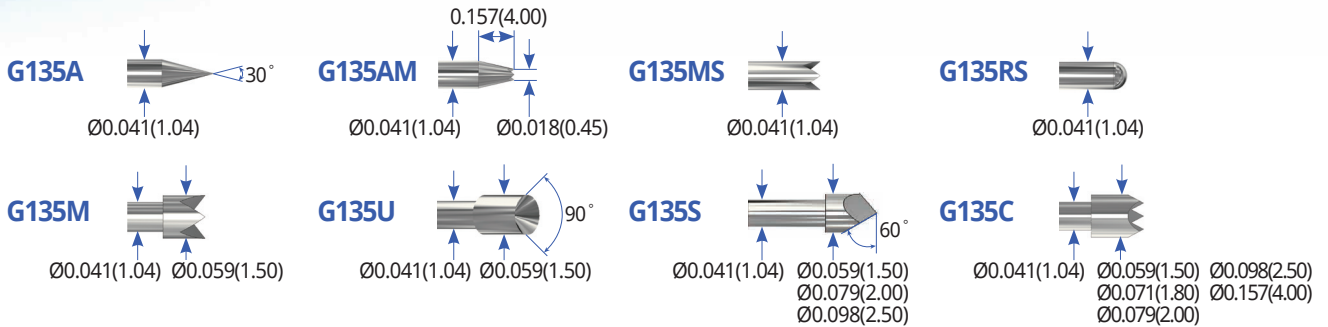

Unit : inch(mm)

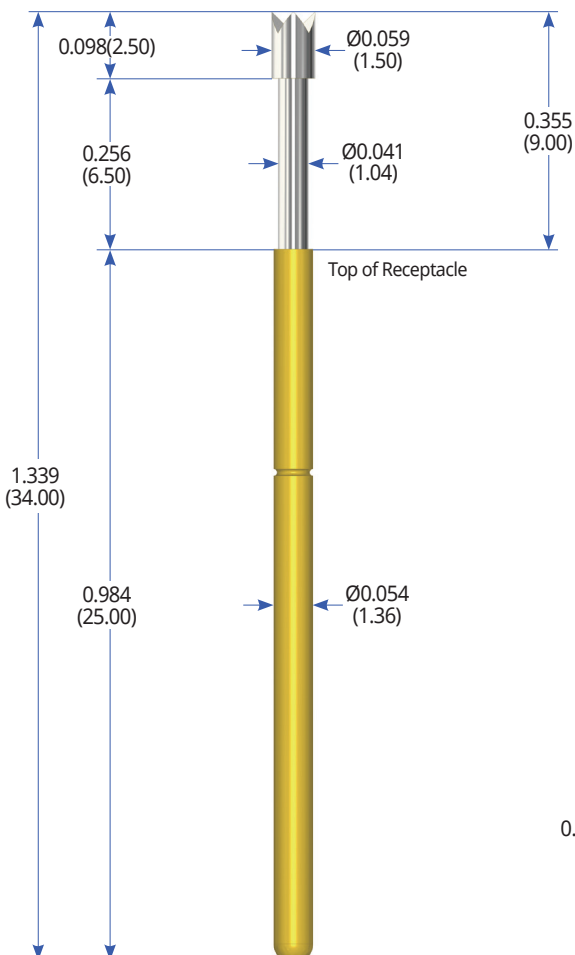

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 6amps
- Probe Resistance : Less than 30m Ω

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force 20%	Oz(Grams)
Recommended Travel 0.169(4.3mm)	Full Travel 0.256(6.5mm)
5.119(145)	6.884 C Type Only (195)
6.001(170)	8.119(230)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Nickel Plated (or Gold Plated)
- Square Post : Brass, Gold Plated

G170W Wire-Wrap Receptacle

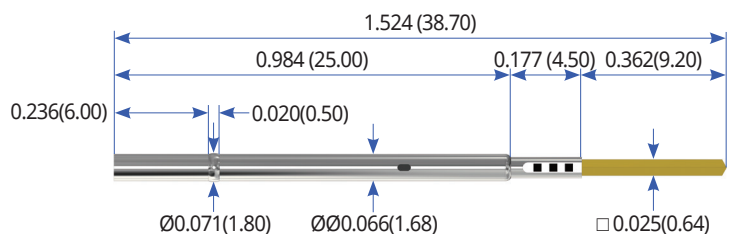

G170DW Wire-Wrap Receptacle(Two Press rings)



G170SW Solder Cup Receptacle



G170TW Crimp Style Receptacle

