



0.100(2.54) Test Centers G165

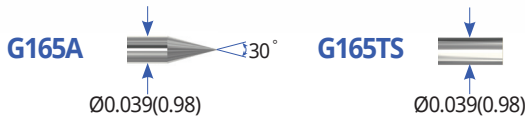

Unit : inch(mm)

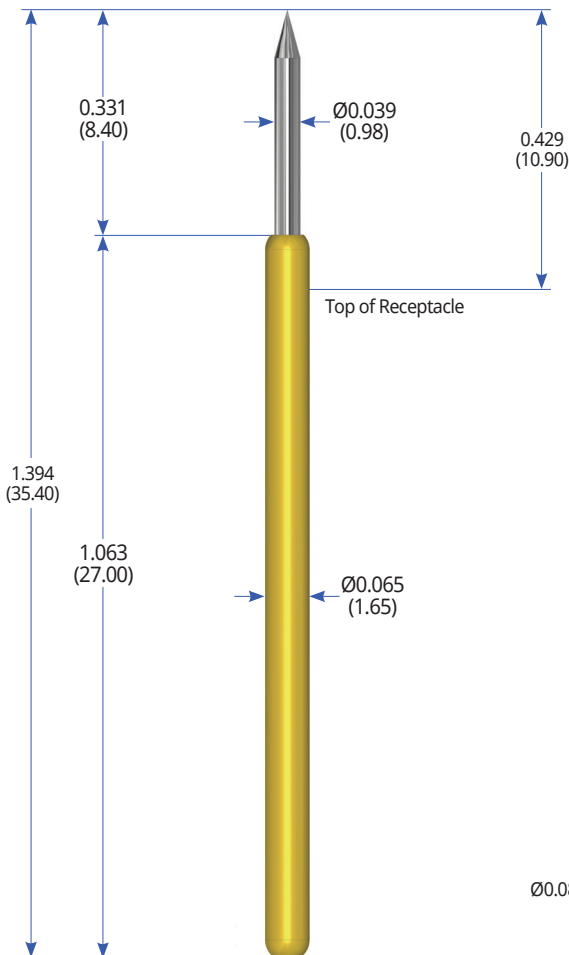

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 8amps
- Probe Resistance : Less than 30mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Brass, Gold Plated
- Spring : Music Wire
- Ball : Stainless Steel, Gold Plated

Spring Force ±20%	Oz(Grams)
Recommended Travel 0.201(5.1mm)	Full Travel 0.303(7.7mm)
3.318(94)	4.448(126)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated
- Round Post : Brass, Nickel Plated

G165W-R1 No Termination Receptacle

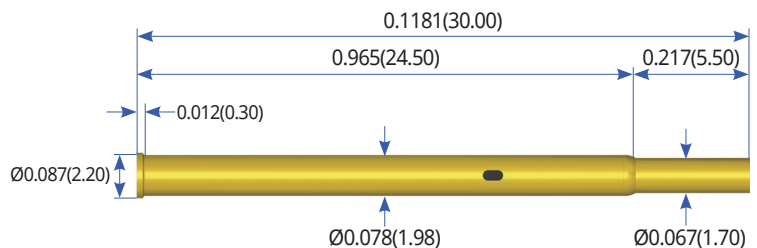

G165SW Solder Cup Receptacle

