



# 0.187(4.75) Test Centers G265

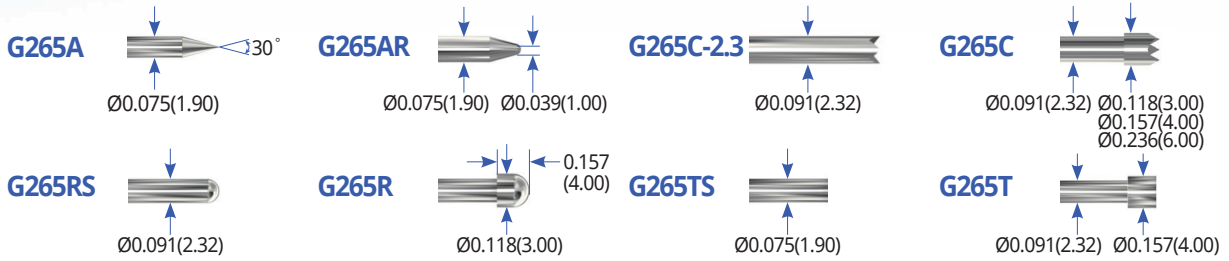

Unit : inch(mm)

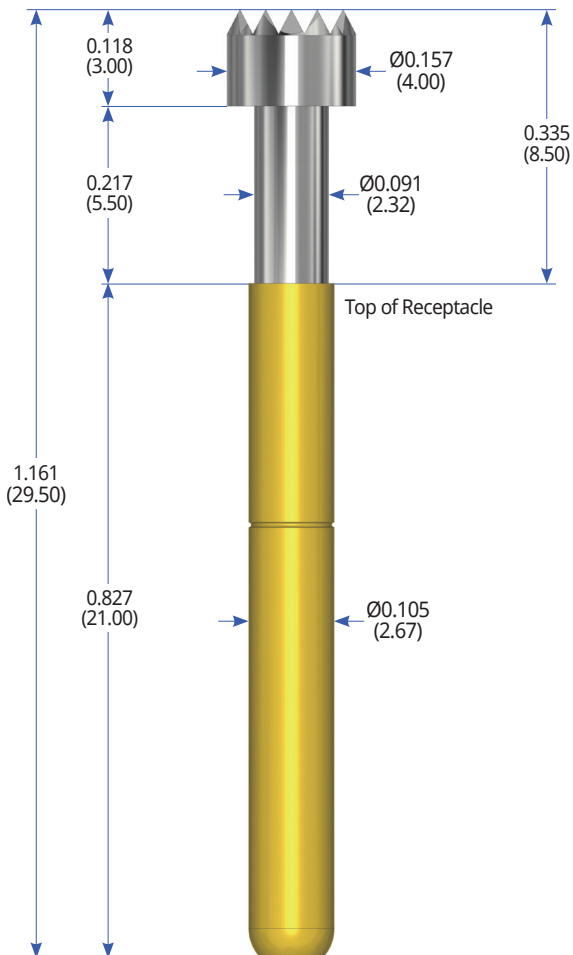

## Probe Specifications

### Electrical(Static Conditions)

- Current Rating : 8amps
- Probe Resistance : Less than 30m $\Omega$

### Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Brass, Gold Plated
- Spring : Music Wire, Stainless Steel Wire
- Ball : Stainless Steel, Gold Plated

Spring Force $\pm 20\%$	Oz(Grams)
Recommended Travel	Full Travel
0.146(3.7mm)	0.217(5.5mm)
8.401(238)	10.343(293)

## Receptacle Specifications

- Housing : Work Hardened Nickel Silver or Phosphor Bronze or Brass, Gold Plated
- Round Post : Brass, Nickel Plated

### G265TW Round Post Receptacle

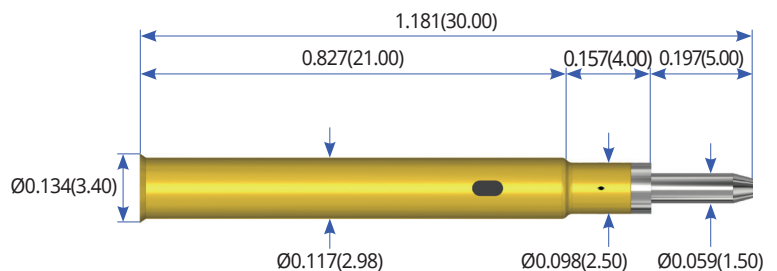

### G265SW Solder Cup Receptacle

