

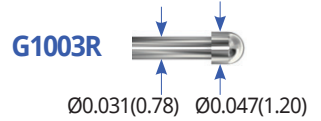
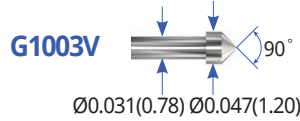
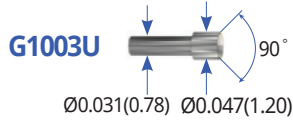
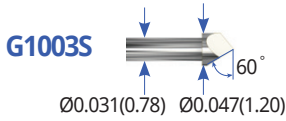
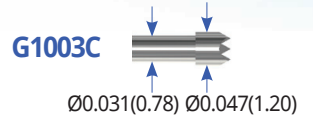
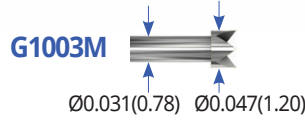
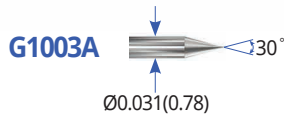


0.075(1.91) Test Centers G1003

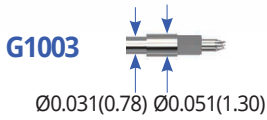

Unit : inch(mm)

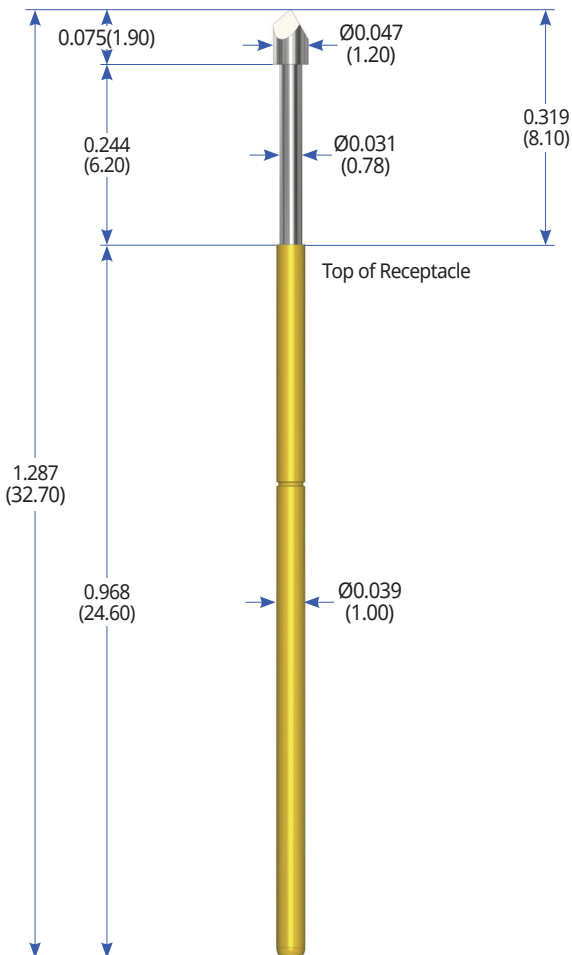

Probe Specifications

Electrical(Static Conditions)

- Current Rating : 6amps
- Probe Resistance : Less than 30mΩ

Materials and Finishes


- Plunger : Hardened Beryllium Copper, Palladium Plated (Optional Gold Plated)
- Barrel : Phosphor Bronze, Gold Plated
- Spring : Music Wire

Spring Force ±20%	Oz(Grams)
Recommended Travel	Full Travel
0.161(4.1mm)	0.244(6.2mm)
3.707(105)	4.942(140)

Receptacle Specifications

- Housing : Work Hardened Nickel Silver, Nickel Plated
- Square Post : Brass, Gold Plated

G1003W Wire-Wrap Receptacle

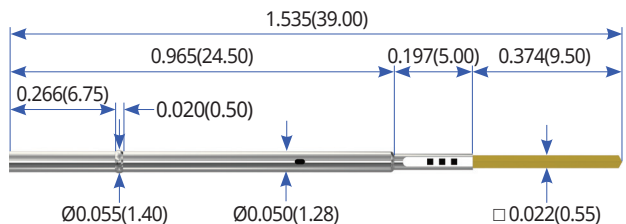

G1003SW Solder Cup Receptacle



G1003TW Crimp Style Receptacle

