



Pneumatic Test Probe Air PROBE-M

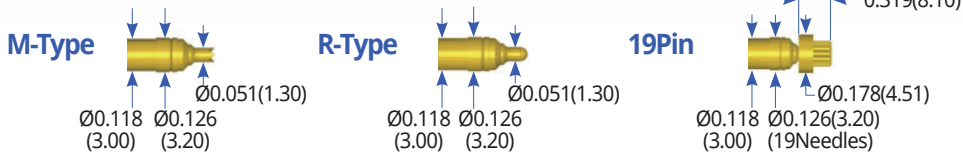

Unit : inch(mm)

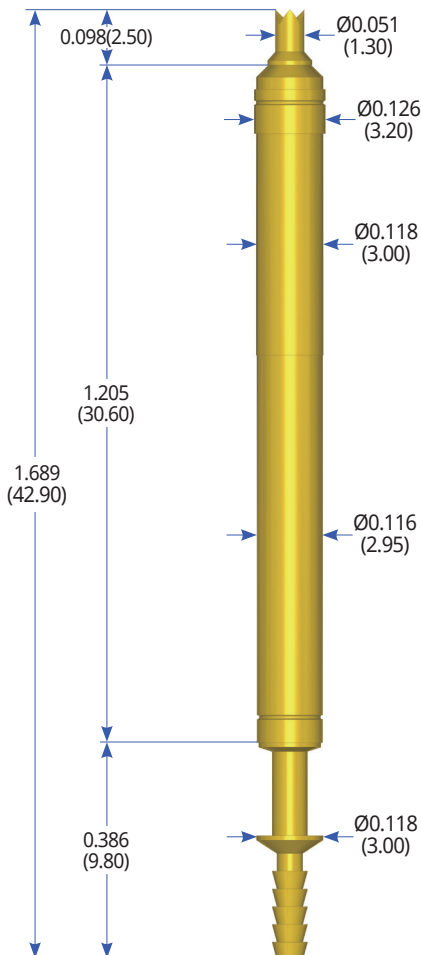

Probe Specifications

Electrical(Static Conditions)

- Operating medium : Compressed air(Filterd, Oil-Free)

Materials and Finishes

- Plunger : Hardened Beryllium Copper, Gold Plated
- Barrel : Brass, Gold Plated
- Spring : Stainless Steel Wire
- Maximum Travel : 0.433(11.0mm)

Electrical Data

- Current Rating : 10amps
- Probe Resistance : Less than 30m Ω