


MBブッシング 各種寸法詳細図

図1-7-2

MBブッシングG タイプ1

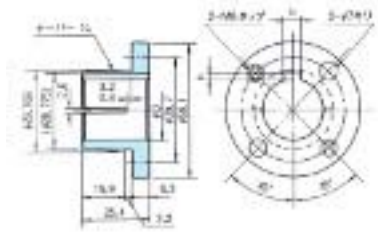


新JIS			旧JIS		
D	b	h	b	h	
10	3	1.4	4	1.5	
11	4	1.8	-	-	
12	4	1.8	4	1.5	
14	5	2.3	5	2	
15	5	2.3	5	2	
16	5	2.3	5	2	
18	6	2.8	5	2	
19	6	2.8	-	-	
20	6	2.8	5	2	

MBブッシングG タイプ2




新JIS			旧JIS		
D	b	h	b	h	
22	6	6.5	7	6.9	
24	8	5.8	7	5.9	
25	8	5.3	7	5.4	

MBブッシングH タイプ1

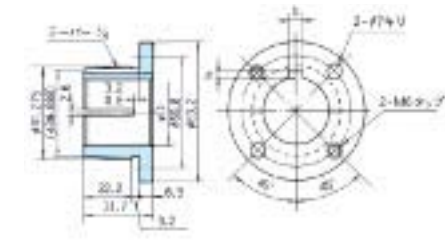


新JIS			旧JIS		
D	b	h	b	h	
20	6	2.8	5	2	
22	6	2.8	7	3	
24	8	3.3	7	3	
25	8	3.3	7	3	
28	8	3.3	7	3	
30	8	3.3	7	3	

MBブッシングH タイプ2

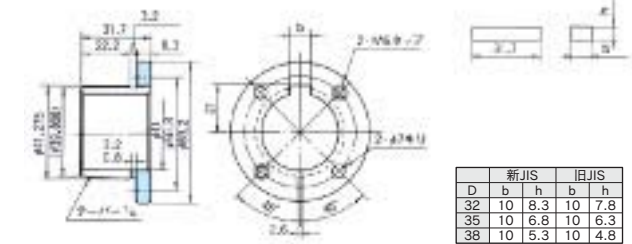


新JIS			旧JIS		
D	b	h	b	h	
32	10	8.3	10	7.8	
35	10	6.8	10	6.3	
38	10	5.3	10	4.8	

MBブッシングP1 タイプ1

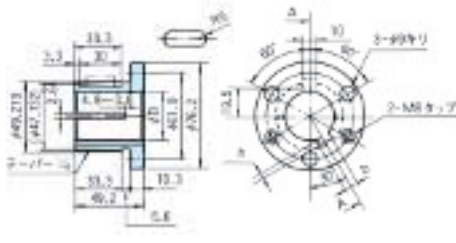


新JIS			旧JIS		
D	b	h	b	h	
20	6	2.8	5	2	
22	6	2.8	7	3	
24	8	3.3	7	3	
25	8	3.3	7	3	
28	8	3.3	7	3	
30	8	3.3	7	3	
32	10	3.3	10	3.5	
35	10	3.3	10	3.5	

MBブッシングP1 タイプ2

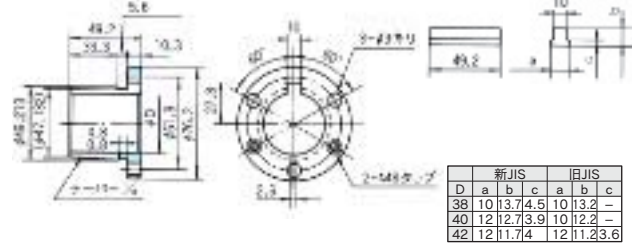


新JIS			旧JIS		
D	a	b	c	a	b
38	10	13.7	4.5	10	13.2
40	12	12.7	3.9	10	12.2
42	12	11.74	-	12	11.23

MBブッシングQ1 タイプ1

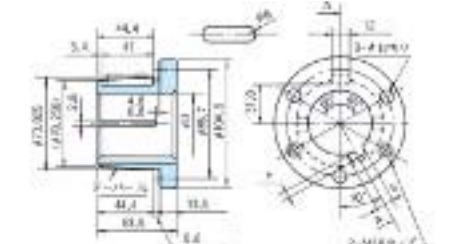


新JIS			旧JIS		
D	b	h	b	h	
20	6	2.8	5	2	
22	6	2.8	7	3	
24	8	3.3	7	3	
25	8	3.3	7	3	
28	8	3.3	7	3	
30	8	3.3	7	3	
32	10	3.3	10	3.5	
35	10	3.3	10	3.5	
38	10	3.3	10	3.5	
40	12	3.3	10	3.5	
42	12	3.3	12	3.5	
45	14	3.8	12	3.5	
48	14	3.8	12	3.5	
50	14	3.8	12	3.5	

MBブッシングQ1 タイプ2

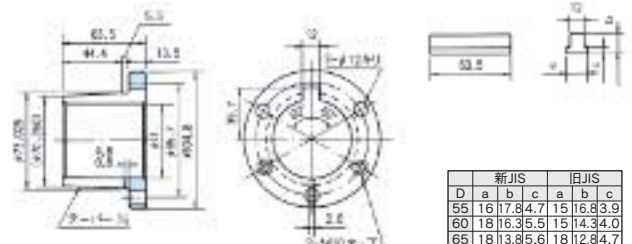


新JIS			旧JIS		
D	a	b	c	a	b
55	16	17.8	4.7	15	16.8
60	18	16.3	5.5	15	14.3
65	18	13.8	5.6	18	12.8

MBブッシングQ2 タイプ1

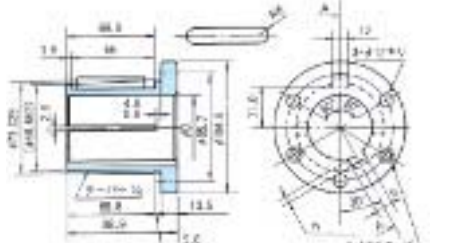


新JIS			旧JIS		
D	b	h	b	h	
28	8	3.3	7	3	
30	8	3.3	7	3	
32	10	3.3	10	3.5	
35	10	3.3	10	3.5	
38	10	3.3	10	3.5	
40	12	3.3	10	3.5	
42	12	3.3	12	3.5	
45	14	3.8	12	3.5	
48	14	3.8	12	3.5	
50	14	3.8	12	3.5	

MBブッシングQ2 タイプ2

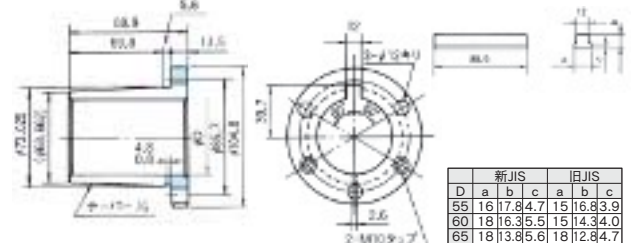


新JIS			旧JIS		
D	a	b	c	a	b
55	16	17.8	4.7	15	16.8
60	18	16.3	5.5	15	14.3
65	18	13.8	5.6	18	12.8

MBブッシングR1 タイプ1

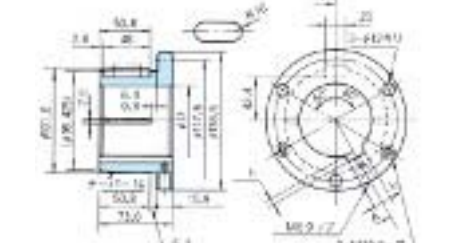

新JIS			旧JIS		
D	b	h	b	h	
30	8	3.3	7	3	
32	10	3.3	10	3.5	
35	10	3.3	10	3.5	
38	10	3.3	10	3.5	
40	12	3.3	10	3.5	
42	12	3.3	12	3.5	
45	14	3.8	12	3.5	
48	14	3.8	12	3.5	
50	14	3.8	12	3.5	
55	16	4.3	15	5	
60	18	4.4	15	5	
65	18	4.4	18	6	
70	20	4.9	18	6	

MBブッシングR1 タイプ2

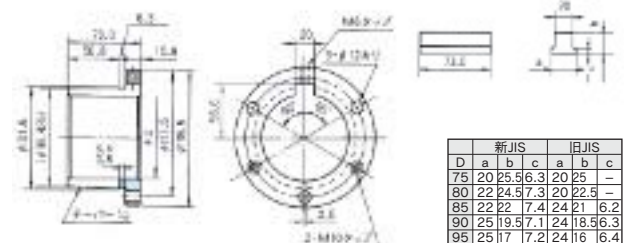

新JIS			旧JIS		
D	a	b	c	a	b
75	20	25.5	6.3	20	25
80	22	24.5	7.3	20	22.5
85	22	22	7.4	24	21
90	25	19.5	7.1	24	18.5
95	25	17	7.2	24	16

