




レジャーサの寸法

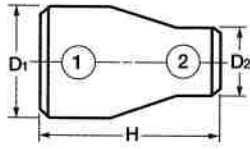


同心レジャーサ1形
R(C)1

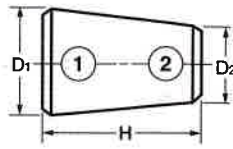

同心レジャーサ2形
R(C)2

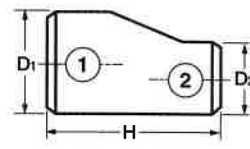

偏心レジャーサ1形
R(E)1

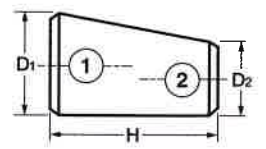

偏心レジャーサ2形
R(E)2

単位：mm

径の呼び ①×②		外径		端面から端面 までの距離
A	B	D ₁	D ₂	
20×15	3/4×1/2	27.2	21.7	38.1
25×20	1×3/4	34.0	27.2	50.8
25×15	1×1/2		21.7	
32×25	1 1/4×1	42.7	34.0	50.8
32×20	1 1/4×3/4		27.2	
32×15	1 1/4×1/2		21.7	
40×32	1 1/2×1 1/4	48.6	42.7	63.5
40×25	1 1/2×1		34.0	
40×20	1 1/2×3/4		27.2	
40×15	1 1/2×1/2		21.7	
50×40	2×1 1/2	60.5	48.6	76.2
50×32	2×1 1/4		42.7	
50×25	2×1		34.0	
50×20	2×3/4		27.2	
65×50	2 1/2×2	76.3	60.5	88.9
65×40	2 1/2×1 1/2		48.6	
65×32	2 1/2×1 1/4		42.7	
65×25	2 1/2×1		34.0	
80×65	3×2 1/2	89.1	76.3	88.9
80×50	3×2		60.5	
80×40	3×1 1/2		48.6	
80×32	3×1 1/4		42.7	
90×80	3 1/2×3	101.6	89.1	101.6
90×65	3 1/2×2 1/2		76.3	
90×50	3 1/2×2		60.5	
90×40	3 1/2×1 1/2		48.6	
90×32	3 1/2×1 1/4		42.7	
100×90	4×3 1/2	114.3	101.6	101.6
100×80	4×3		89.1	
100×65	4×2 1/2		76.3	
100×50	4×2		60.5	
100×40	4×1 1/2		48.6	

径の呼び ①×②		外径		端面から端面 までの距離
A	B	D ₁	D ₂	
125×100	5×4	139.8	114.3	127.0
125×90	5×3 1/2		101.6	
125×80	5×3		89.1	
125×65	5×2 1/2		76.3	
125×50	5×2		60.5	
150×125	6×5		165.2	
150×100	6×4	114.3		
150×90	6×3 1/2	101.6		
150×80	6×3	89.1		
150×65	6×2 1/2	76.3		
200×150	8×6	216.3	165.2	152.4
200×125	8×5		139.8	
200×100	8×4		114.3	
200×90	8×3 1/2		101.6	
250×200	10×8	267.4	216.3	177.8
250×150	10×6		165.2	
250×125	10×5		139.8	
250×100	10×4		114.3	
300×250	12×10	318.5	267.4	203.2
300×200	12×8		216.3	
300×150	12×6		165.2	
300×125	12×5		139.8	
350×300	14×12	355.6	318.5	330.2
350×250	14×10		267.4	
350×200	14×8		216.3	
350×150	14×6		165.2	
400×350	16×14	406.4	355.6	355.6
400×300	16×12		318.5	
400×250	16×10		267.4	
400×200	16×8		216.3	
450×400	18×16	457.2	406.4	381.0
450×350	18×14		355.6	
450×300	18×12		318.5	