

サドルバンド(ステンレス)

M168S MB



| 寸法 | H | P | φA | 価格 | 入数 |
|-----|-----|-----|-----|-------|----------|
| 10 | 16 | 35 | 4.0 | 40 | 200/3000 |
| 13 | 18 | 35 | 4.2 | 40 | 200/2400 |
| 16 | 22 | 43 | 4.2 | 46 | 100/1200 |
| 20 | 26 | 46 | 4.2 | 50 | 100/1200 |
| 25 | 33 | 57 | 4.2 | 80 | 100/1400 |
| 30 | 40 | 67 | 4.5 | 140 | 100/1200 |
| 40 | 48 | 78 | 4.5 | 160 | 100/1200 |
| 50 | 60 | 84 | 4.5 | 220 | 50/600 |
| 65 | 76 | 117 | 7.0 | 530 | 40 |
| 75 | 89 | 125 | 7.0 | 720 | 30 |
| 100 | 114 | 148 | 7.0 | 990 | 20 |
| 125 | 140 | 175 | 7.0 | 1,460 | 20 |
| 150 | 165 | 198 | 7.0 | 1,740 | 20 |

◎材質: SUS304

サドルバンド(鉄)

M168 MB

 


| 寸法 | H | P | φA | 価格 | 入数 |
|-----|-----|-----|-----|-------|----------|
| 10 | 16 | 35 | 4.0 | 16 | 200/3000 |
| 13 | 18 | 35 | 4.2 | 16 | 200/2400 |
| 16 | 22 | 43 | 4.2 | 20 | 100/1200 |
| 20 | 26 | 46 | 4.2 | 22 | 100/1200 |
| 25 | 33 | 57 | 4.2 | 30 | 100/1400 |
| 30 | 40 | 67 | 4.5 | 46 | 100/1200 |
| 40 | 48 | 78 | 4.5 | 56 | 100/1200 |
| 50 | 60 | 84 | 4.5 | 72 | 50/600 |
| 65 | 76 | 117 | 7.0 | 430 | 30 |
| 75 | 89 | 125 | 7.0 | 500 | 30 |
| 100 | 114 | 148 | 7.0 | 640 | 20 |
| 125 | 140 | 175 | 7.0 | 930 | 20 |
| 150 | 165 | 198 | 7.0 | 1,100 | 20 |

◎材質: 鉄 10/ユニクロメッキ, 13-150/亜鉛メッキ

片サドルバンド(ステンレス)

M168SK MB

 


| 寸法 | H | P | A | 価格 | 入数 |
|--------|----|----|----|-----|----------|
| 16 | 22 | 27 | 8 | 82 | 100/1000 |
| 20(22) | 26 | 27 | 8 | 94 | 100/1000 |
| 25(28) | 33 | 29 | 10 | 120 | 100/1000 |

◎材質: SUS304

片サドルバンド

M168K MB




| 寸法 | H | P | A | 価格 | 入数 |
|--------|----|----|----|----|----------|
| 16 | 21 | 27 | 8 | 34 | 100/1000 |
| 20(22) | 27 | 27 | 8 | 40 | 100/1000 |
| 25(28) | 34 | 29 | 10 | 58 | 100/1000 |

◎材質: 鉄、亜鉛メッキ

巾広サドルバンド(ステンレス)

M168SW MB

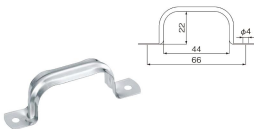


| 寸法 | 価格 | 入数 |
|----|----|----------|
| 16 | 76 | 100/1000 |

◎材質: SUS304

応用バンド

M168A MB

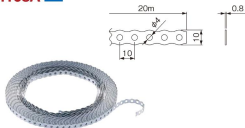

| 寸法 | 価格 | 入数 |
|----|-------|------|
| 10 | 2,520 | 1/25 |

◎材質: SGCC, 亜鉛メッキ