





M1-130-C1


M1-130-L1

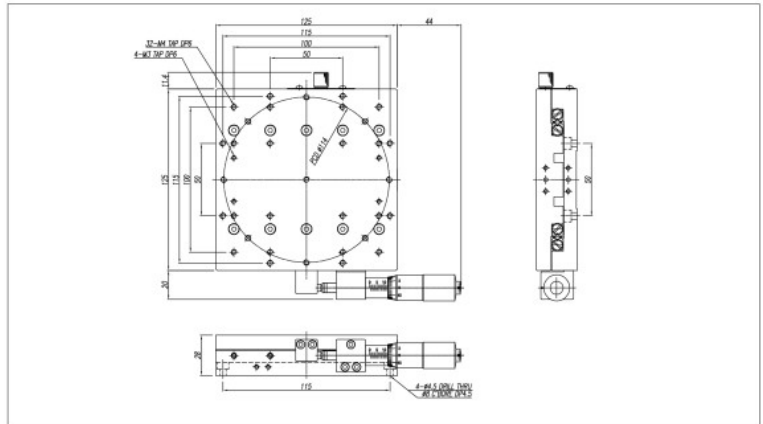

M1-130-R1

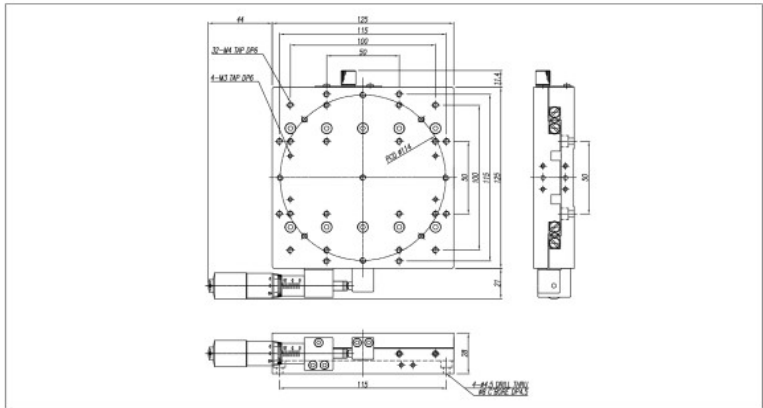

M1-130-C1

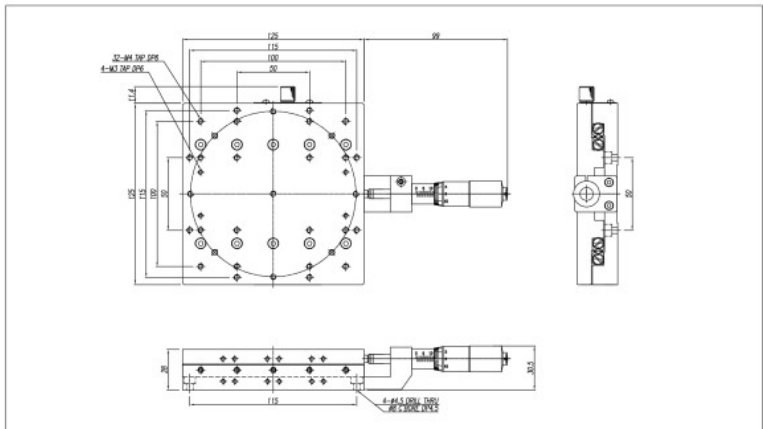

SPECIFICATION	M1-130-L1, R1, C1
Table Dimension(mm)	125×125
Travel Range(mm)	±12.5
Travel Guide	Cross Roller Guide
Readable Resolution(mm)	0.01
Parallelism(mm)	0.03
Running Parallelism(mm)	0.015
Straightness(mm)	0.005
Load Capacity(kg)	20
Material	Steel
Weight(kg)	3.4