





D1-418-L5

## D1-418-L5

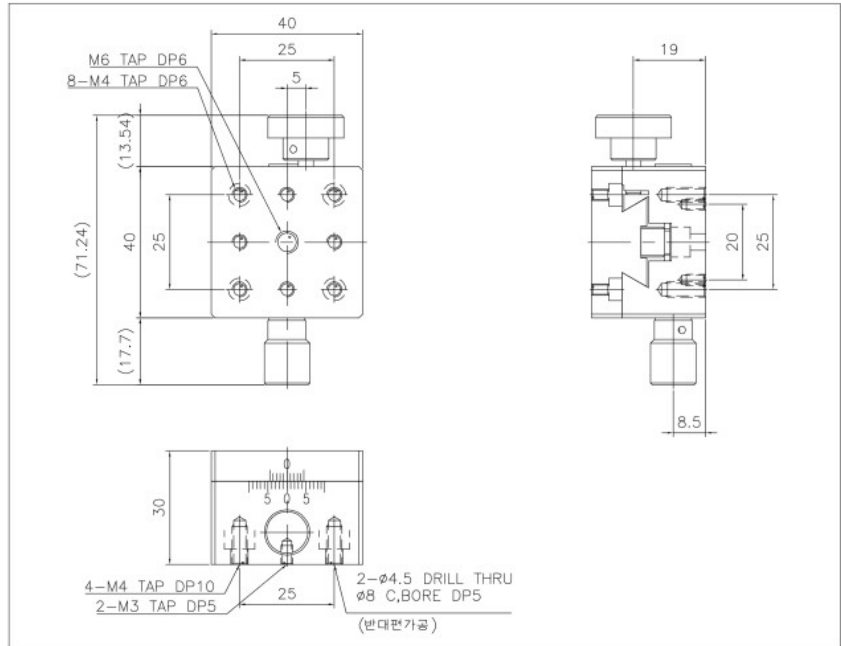

## D1-618-L5

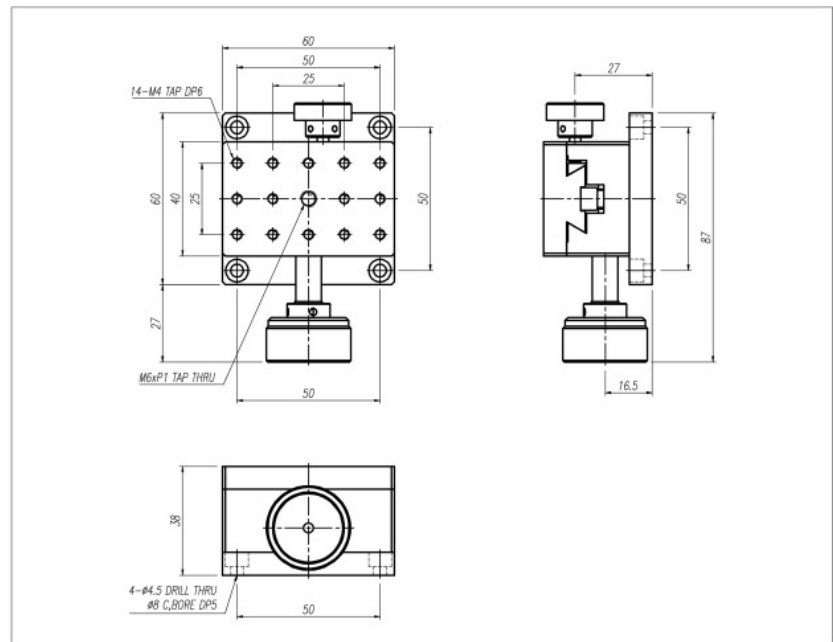

SPECIFICATION	D1-418-L5	D1-618-L5
Table Dimension(mm)	40×40	40×60
Travel Range(mm)	±10	±15
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.06
Straightness(mm)	0.03	
Load Capacity(kg)	2.5	3
Material	Aluminum	
Weight(kg)	0.16	0.31