


D2-418-L5




D2-418-L5

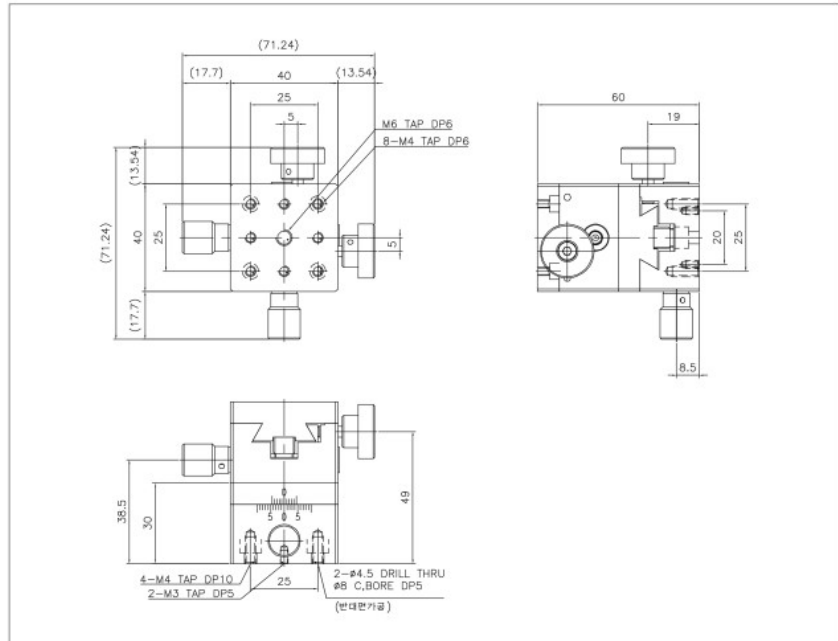

D2-618-L5



D2-618-L5

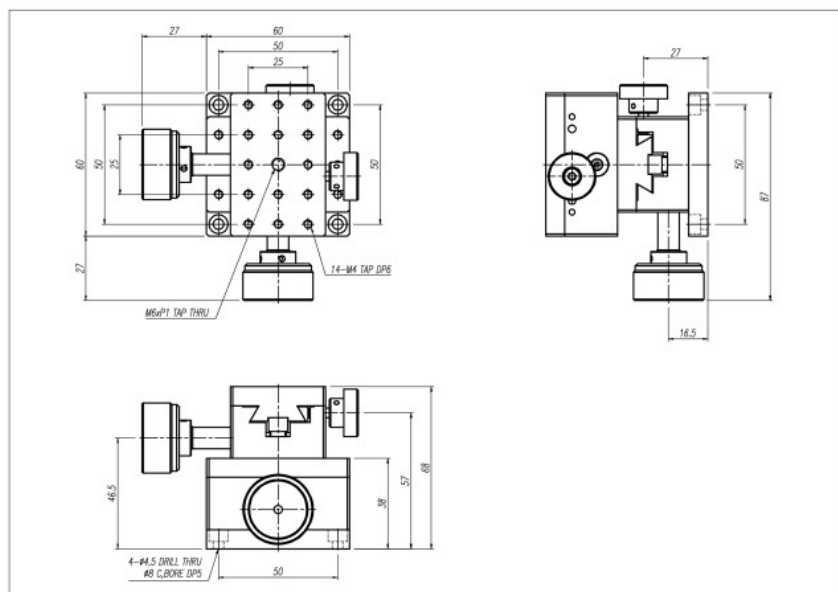

SPECIFICATION	D2-418-L5	D2-618-L5
Table Dimension(mm)	40×40	40×60
Travel Range(mm)	±10	±15
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.06
Straightness(mm)	0.03	
Load Capacity(kg)	2.5	2.7
Material	Aluminum	
Weight(kg)	0.32	0.62