



## D2-918-L5



D2-918-L5

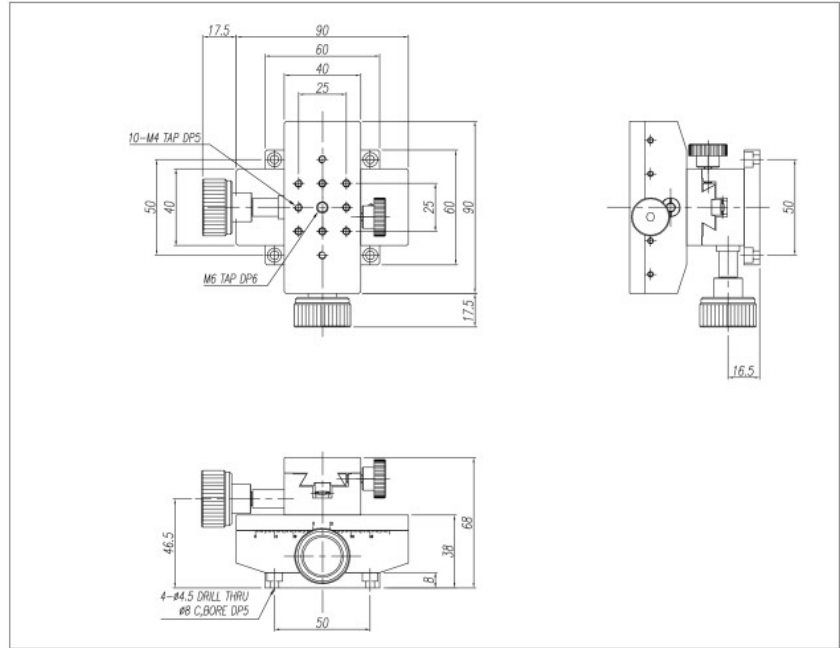

## D2-118-L5

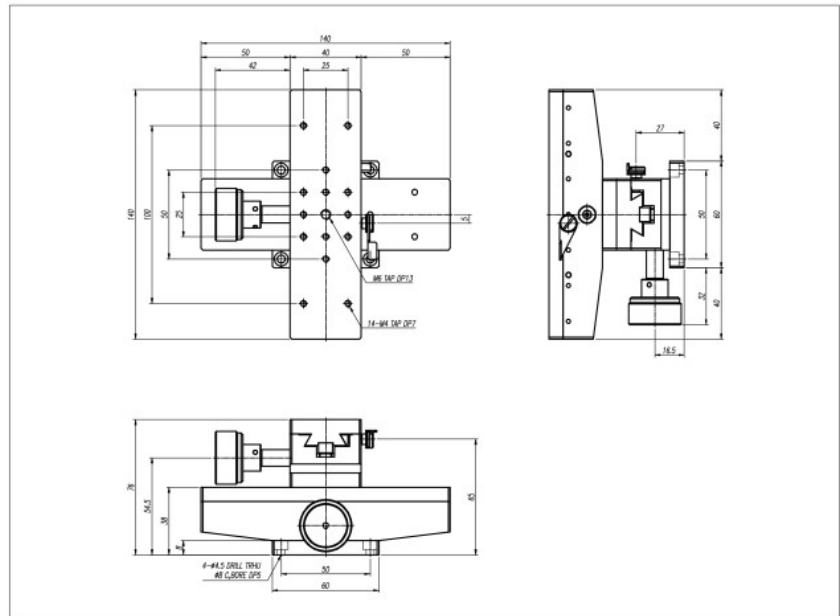

SPECIFICATION	D2-918-L5	D2-118-L5
Table Dimension(mm)	40×90	40×140
Travel Range(mm)	±30	±50
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.08
Straightness(mm)	0.03	
Load Capacity(kg)	3.6	3.5
Material	Aluminum	
Weight(kg)	0.8	1.1