



D3-418-L5W

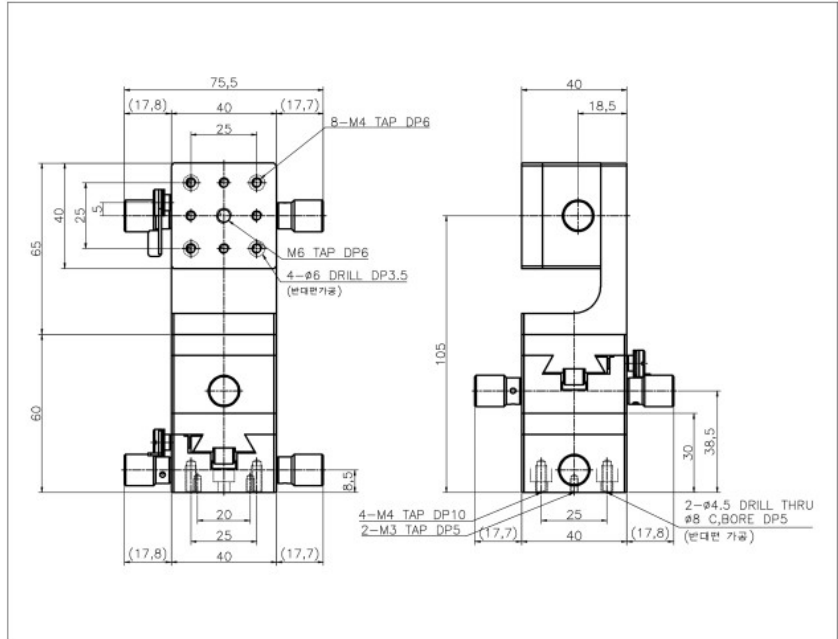

D3-618-L5W



D3-618-L5W

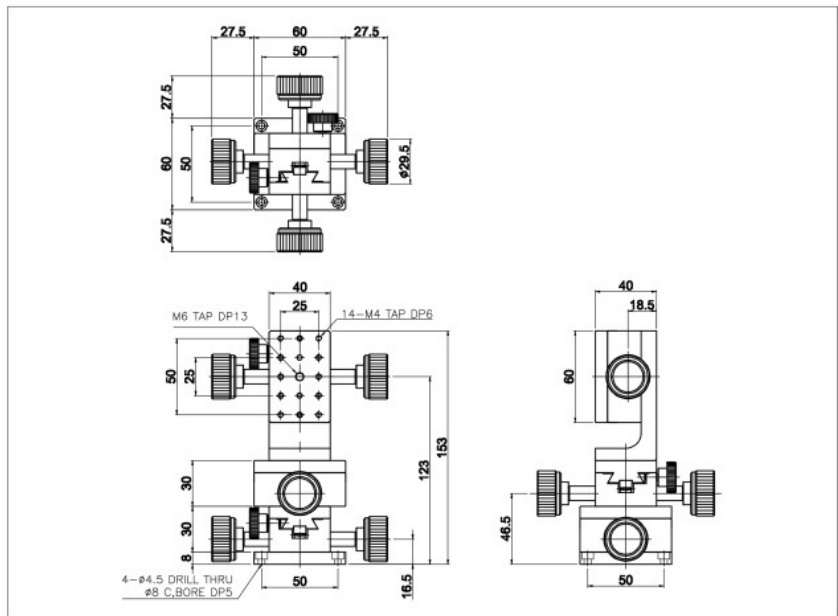

MANUAL STAGE

SPECIFICATION	D3-418-L5W	D3-618-L5W
Table Dimension(mm)	40×40	40×60
Travel Range(mm)	±10	±15
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.06
Straightness(mm)	0.03	
Load Capacity(kg)	1	2
Material	Aluminum	
Weight(kg)	0.8	1.1