



## D3-216-L6



D3-216-L6

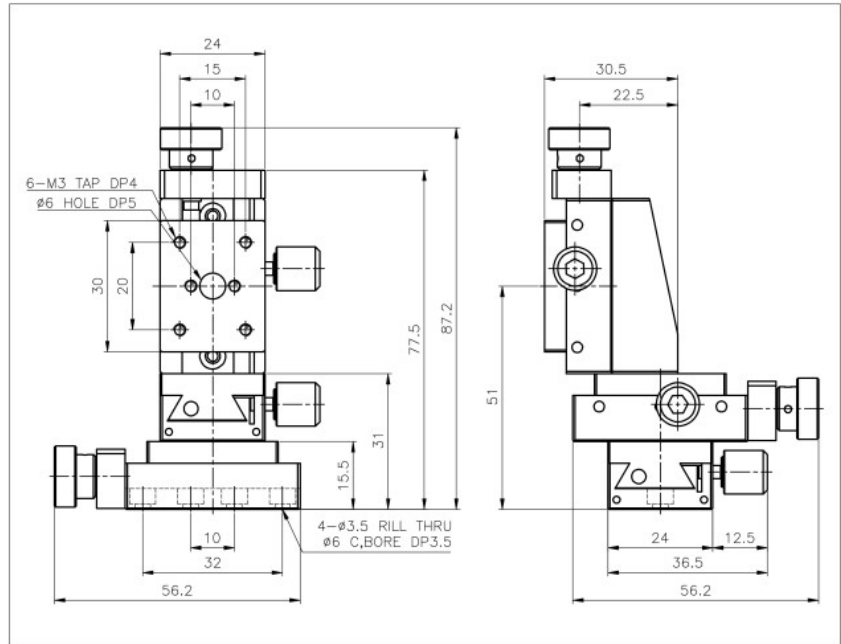

## D3-716-L6

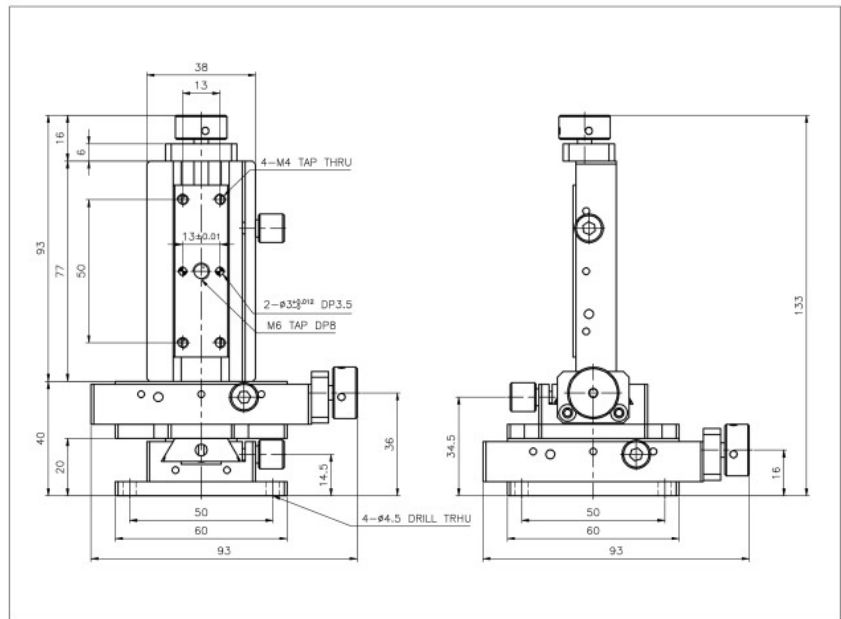

| SPECIFICATION           | D3-216-L6            | D3-716-L6 |
|-------------------------|----------------------|-----------|
| Table Dimension(mm)     | 24×30                | 18×60     |
| Travel Range(mm)        | ±4                   | ±7.5      |
| Travel Guide            | Dovetail Type, Screw |           |
| Readable Resolution(mm) | -                    |           |
| Parallelism(mm)         | 0.05                 | 0.06      |
| Straightness(mm)        | 0.03                 |           |
| Load Capacity(kg)       | 0.5                  | 1         |
| Material                | Brass                | Brass     |
| Weight(kg)              | 0.7                  | 1.4       |