





D4-618-L5

## D4-418-L5

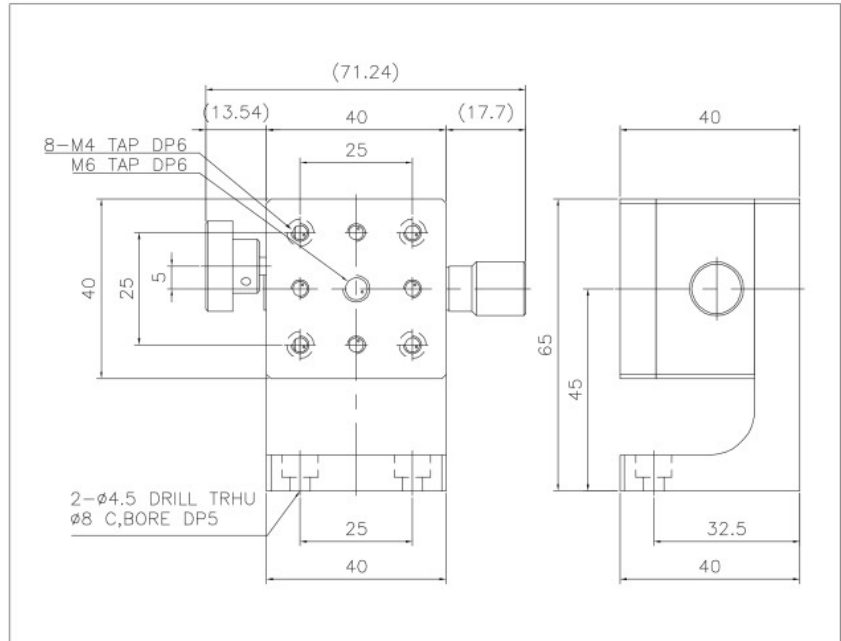

## D4-618-L5

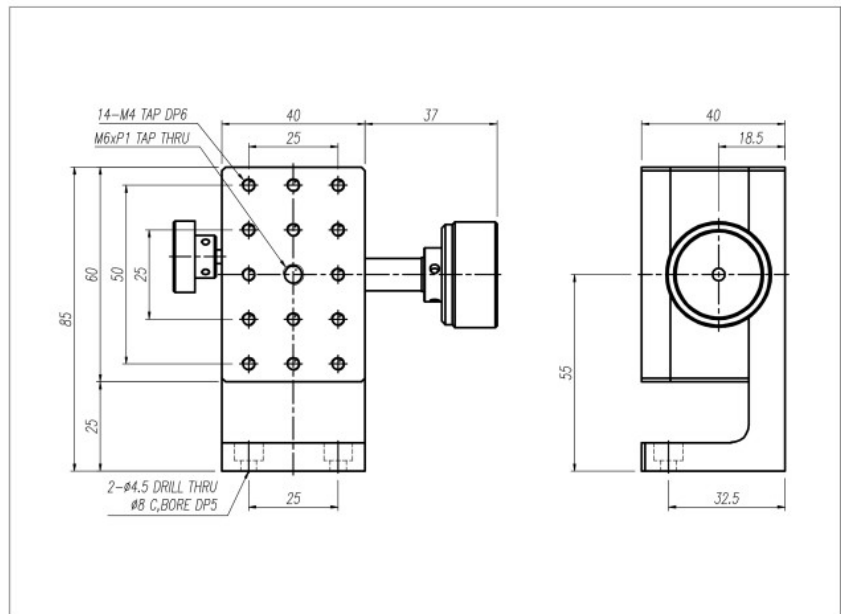

SPECIFICATION	D4-418-L5	D4-618-L5
Table Dimension(mm)	40×40	40×60
Travel Range(mm)	±10	±15
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.06
Straightness(mm)	0.03	
Load Capacity(kg)	1	2
Material	Aluminum	
Weight(kg)	0.24	0.38