



## D4-918-L5



D4-918-L5

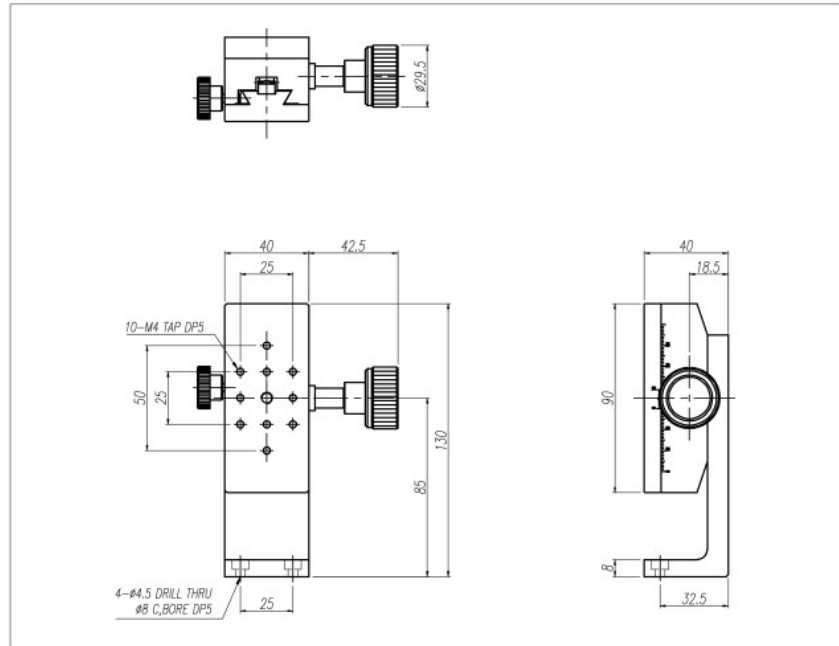

## D4-118-L5

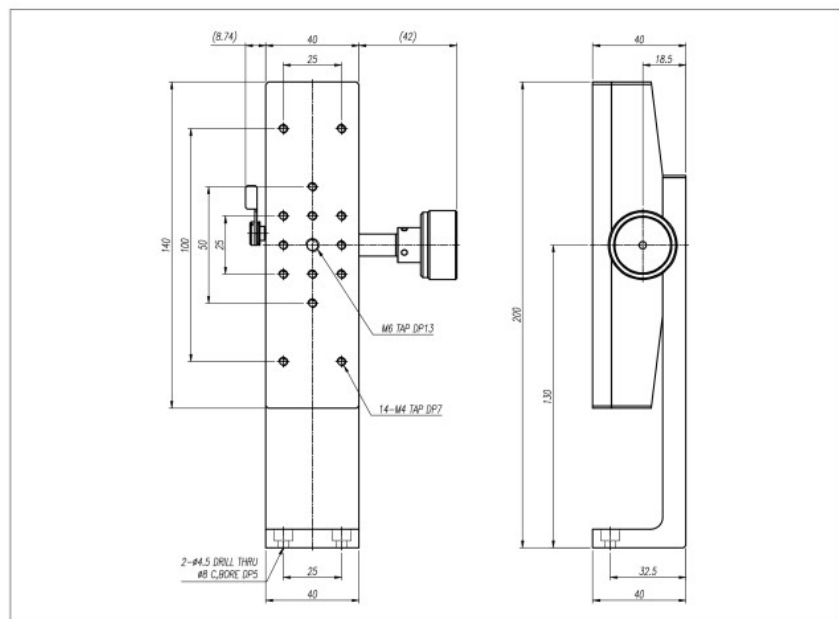

SPECIFICATION	D4-918-L5	D4-118-L5
Table Dimension(mm)	40×90	40×140
Travel Range(mm)	±30	±50
Travel Guide	Dovetail Type, Rack & Pinion	
Readable Resolution(mm)	0.1	
Parallelism(mm)	0.06	0.08
Straightness(mm)	0.03	
Load Capacity(kg)	2	2
Material	Aluminum	
Weight(kg)	0.47	0.67